



 

3

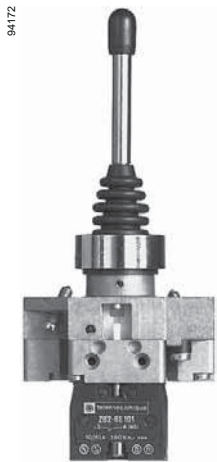

XD2GA8211

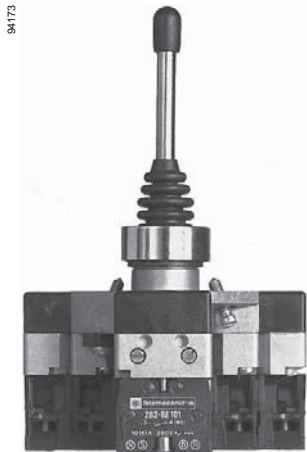

XD2GA8441

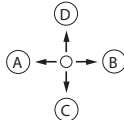Complete units type XD2G, with chromium plated metal bezel					
Interchangeable contacts					
Description	Operation	Spring return to zero position	Bezel finish	Reference	Weight kg/lb
2 direction Fixing centres 90 x 90 mm/ 3.54 x 3.54 in. 	1 notch 1 N/O contact per direction	Without	Shiny	XD2GA8211	0.300/0.661
			Black	XD2GA82117	0.300/0.661
		With	Shiny	XD2GA8221	0.300/0.661
			Black	XD2GA82217	0.300/0.661
	2 notches 2 N/O contacts per direction	Without	Shiny	XD2GA8231	0.500/1.102
			Black	XD2GA82317	0.500/1.102
		With	Shiny	XD2GA8241	0.500/1.102
			Black	XD2GA82417	0.500/1.102
	1 st notch stay put 2 nd notch with spring return to 1 st notch		Shiny	XD2GA8251	0.500/1.102
			Black	XD2GA82517	0.500/1.102
4 direction Fixing centres 90 x 90 mm/ 3.54 x 3.54 in. 	1 notch 1 N/O contact per direction	Without	Shiny	XD2GA8411	0.330/0.728
			Black	XD2GA84117	0.330/0.728
		With	Shiny	XD2GA8421	0.330/0.728
			Black	XD2GA84217	0.330/0.728
	2 notches 2 N/O contacts per direction	Without	Shiny	XD2GA8431	0.550/1.213
			Black	XD2GA84317	0.550/1.213
		With	Shiny	XD2GA8441	0.550/1.213
			Black	XD2GA84417	0.550/1.213
	1 st notch stay put 2 nd notch with spring return to 1 st notch		Shiny	XD2GA8451	0.550/1.213
			Black	XD2GA84517	0.550/1.213