



EN

Datasheet

RS PRO VINYL-INSULATED MALE DISCONNECTORS

Stock number: 178-8384

MAXIMUM ELECTRIC CURRENT:

A.W.G.	12	10
AMP.	20	24


MAXIMUM ELECTRICAL RATING: 75° C 300 VOLTS MAX.

INSULATION MATERIAL: VINYL

TERMINAL MATERIAL: BRASS

INSULATION COLOR: YELLOW

TERMINAL BARREL I.D.: C=3.4MM

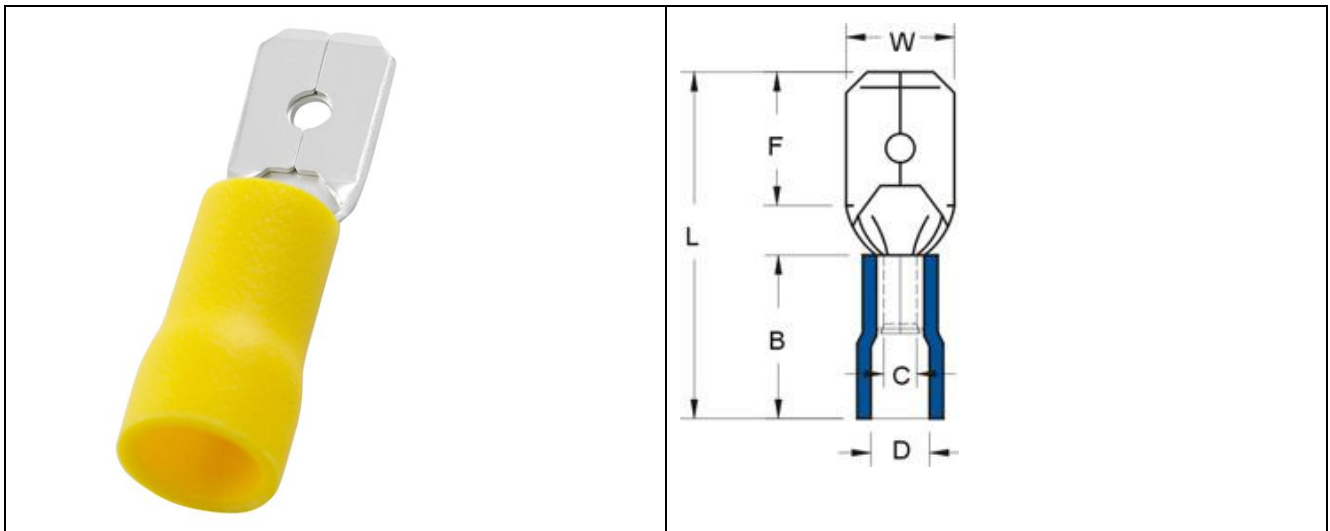

WIRE RANGE A.W.G. mm ²	ITEM NO.	NEMA TAB	DIMENSION inch(mm)					
			W	F	L	B	D	T
12-10 A.W.G. 4-6 mm ²	<input type="checkbox"/> 178-8384	.032X.250 (0.8X6.35)	0.25 6.35	0.303 7.7	0.945 24	0.512 13	0.217 5.500	0.016 0.4