

Chains & sprockets	Wear strips	Side guide brackets & accessories	Levelers
Modular belts & sprockets	Chain & belt return systems	Frame & structure supports	Bearings
Curves & tracks	Side guide solutions	Miscellaneous products	Related information



11220a


www.SystemPlastSmartGuide.com

879M - 880M

Sideflexing chains for magnetic system



Click here for related information.

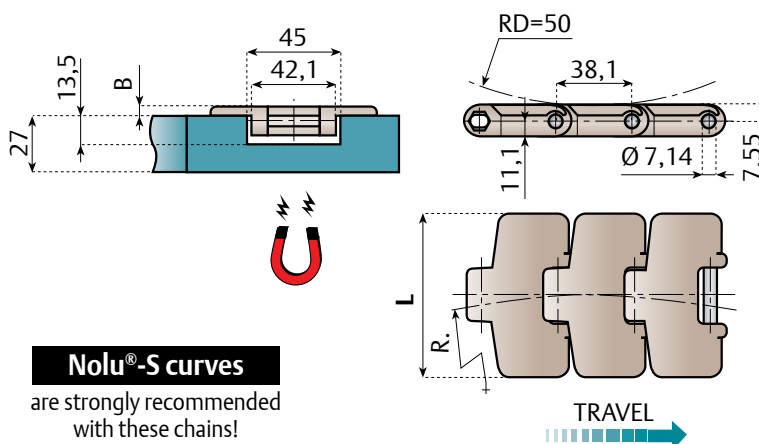

Nolu®-S curves

are strongly recommended with these chains!

Item description	Material plate	Breaking load N	Width L		B Thickness mm	R min.	Weight Kg/m
			mm	inch			
LF880M-K325	LF Brown	5.700	82,5	3 ¼	4	500	1,05
LF880M-K330			83,8	3 ⅞			1,08
LF880M-K450			114,3	4 ½			1,15
LF880M-K750			190,5	7 ½			1,50
NG880M-K325	NG Green	5.200	82,5	3 ¼			1,05
NG880M-K330			83,8	3 ⅞			1,08
NG880M-K450			114,3	4 ½			1,15
NG880M-K750			190,5	7 ½			1,50
LF879M-K325	LF Brown	5.700	82,5	3 ½	4,8	500	1,15
LF879M-K450			114,3	4 ½			1,25
NG879M-K325	NG Green	5.200	82,5	3 ¼			1,15
NG879M-K450			114,3	4 ½			1,25

Standard length: 80 pitches (10 ft. - 3,048 m)

Breaking load according to standard ISO 4348 - DIN 8153

See also:



11260b



11260a



Information about this product is only available on our Smart Guide™ website.