



**1748-BL**
**Steel tooth nylon cable ties, natural colour**

CE

Material: polyamide PA 6.6 + steel  
 Self-extinguishing class: UL 94-V2  
 Working temperature: -40 °C ÷ +85 °C  
 Minimum installation temperature: -10 °C  
 Resistance to chemicals: Good resistance to bases, oils, greases, chloride solvents. Limited resistance to acids. Not resistant to phenols  
 Reference standards: EN 62275:2015-02  
 Classification: type 1 (EN)

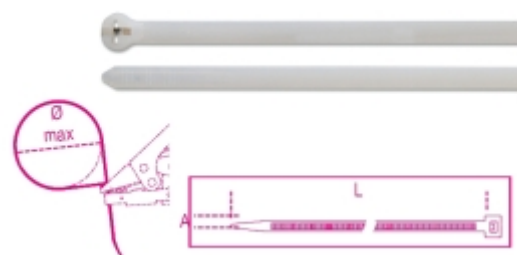

Please indicate number of cable ties, and not of packages, in your order

	art.	A mm	L mm	Ø MAX mm	F MAX N
<b>BMBL1025</b>	BMBL1025	2.5	100	20.5	180
<b>BMBL2025</b>	BMBL2025	2.5	200	52.5	180
<b>BMBL1436</b>	BMBL1436	3.6	140	33.0	250
<b>BMBL2048</b>	BMBL2048	4.8	200	49.5	360
<b>BMBL3048</b>	BMBL3048	4.8	300	81.0	360
<b>BMBL3748</b>	BMBL3748	4.8	370	103.5	360
<b>BMBL3776</b>	BMBL3776	7.6	370	103.5	780