




HYDNUT165-E [🔗](#)

Hydraulic nut

HYDNUT..-E

Technical information

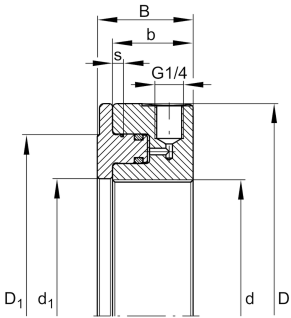

Your current product variant

Series	E	metric fine pitch thread/trapezoid thread
--------	---	---

Technical data

d	M165x3	Thread
D	240 mm	Outer Diameter
B	47 mm	Width
b	40 mm	Width press ring
D 1	211 mm	
d 1	166 mm	
s	6 mm	Stroke, max.
	92.4 cm²	Piston surface
	600 bar	Pressure, max.
	554 kN	Drive-up force, max.
≈m	9.1 kg	Weight

Additional information

1 pc. Hydraulic nut, 3 pcs. Clamping screws, 1 pc. Screw plug, 1 pc. Connection nipple, 3 pcs. to 5 pcs. Threaded pins, 1 pc. Hand lever, 1 pc. Replacement seal set, 1 pc. User manual	Delivery scope
--	----------------