



2610Z0

HeadsUp Lite™

Headlamp

The 2610Z0 provides hands-free light where you need it, when you need it. A dual mode button activates all 3 LEDs for full brightness, or just 1 to extend battery life. The adjustable cloth strap fits comfortably and securely on your head, while the rubber strap grips tightly to hard hats and helmets. Both are included, as well as 3 AAA alkaline batteries. Certified to ATEX Zone 0 (Category 1).



DIMENSIONS

Length	1.49" (3.8 cm)
--------	----------------

MATERIALS

Body	Anti-static Impact Modified PC/PBT
O-Ring	Ethylene Propylene
Lens	Anti-static coated Polycarbonate (PC)
Contact Spring Retainer	Stainless Steel / Brass Nickel

COLOURS

 Black

LIGHT SPECS

Lamp Type	LED
-----------	-----

POWER

Battery Size	AAA
Battery Type	Alkaline
Battery Quantity	3
Batteries Included	yes
Volts	4.5v

WEIGHT

Weight With Batteries	3.2 oz (91 gr)
Weight Without Batteries	1.9 oz (54 gr)
Packaged Weight	6.3 oz (179 gr)

SWITCH

Switch Type	Push Button
Light Modes	On / Off

CERTIFICATIONS

ATEX Zone 0

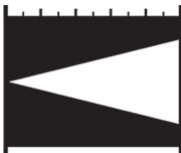
Peli
c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999
info@peli.com • www.peli.com

OTHER

Minimum Pack
Military
Package Code

1
yes
C

Document created on 05-09-25

FL1 STANDARD	HIGH	LOW
	30 LUMENS	14 LUMENS
	19h 0mins	47h 0mins
	28m	19m
	194cd	91cd
	IPX4	

ACCESSORIES