


Control unit, hand switch

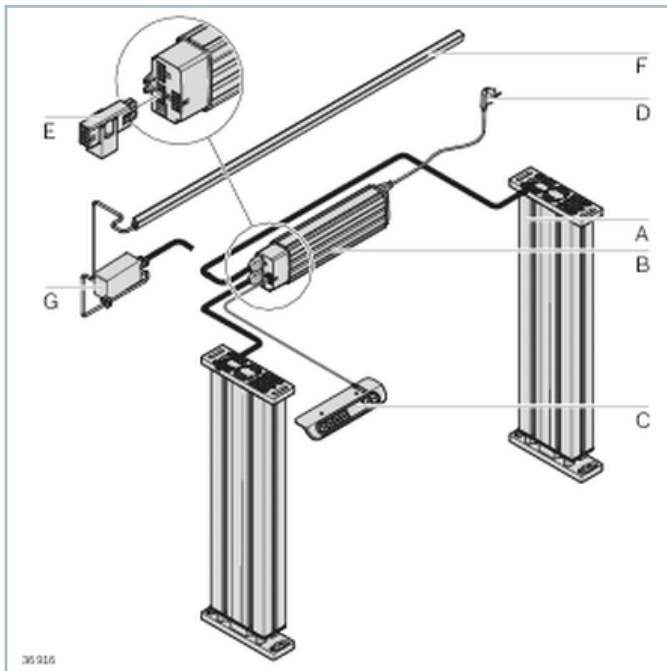


- B→Control unit
- C→Hand switch

[PDF](#) Assembly instructions

Product description


Control unit (B)

- Control for synchronization of 1, 2, or 3 lifting modules in parallel operation
- Duty cycle: 10% (= 2 min ON, 18 min OFF)

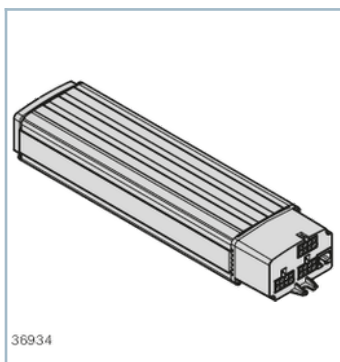


Hand switch (C)

- For operating the controller, with push button for height adjustment and 4 memory buttons to store the different positions, with display, cable length: ~ 1.8 m

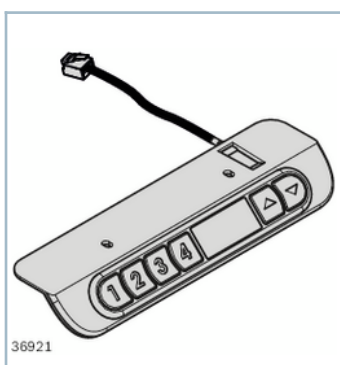


Fields of application

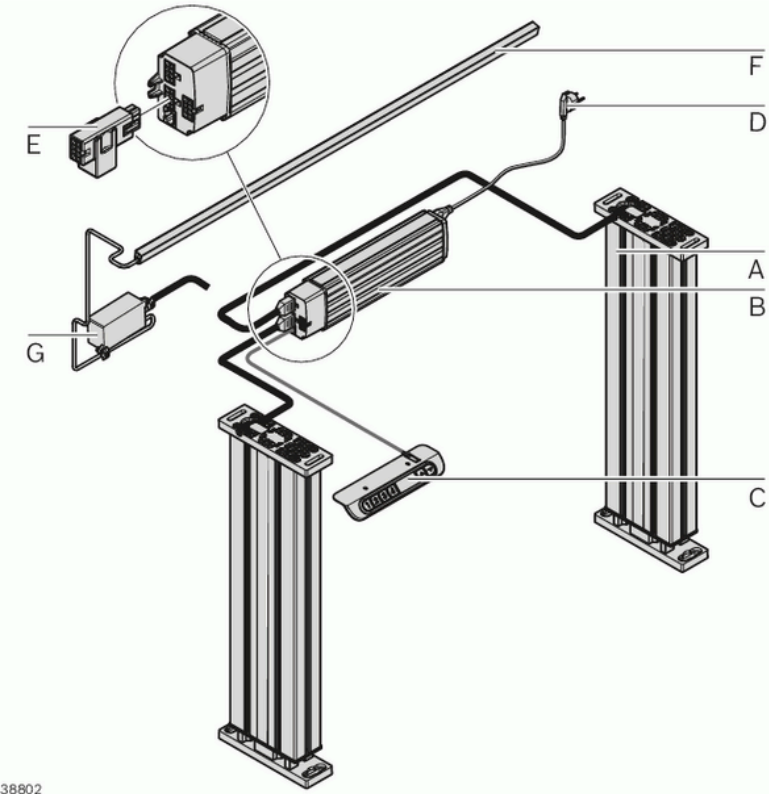

Dimensions


Control unit

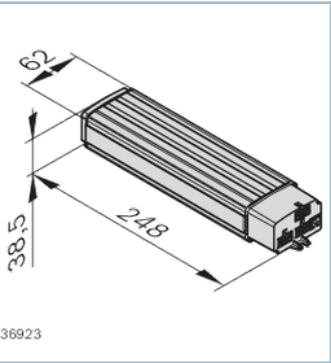

Ordering parameter with configurable material number

		3842559921	3842559922	3842559923	3842559931	3842559932	3842559933	3842559940
--	--	------------	------------	------------	------------	------------	------------	------------

Hand switch

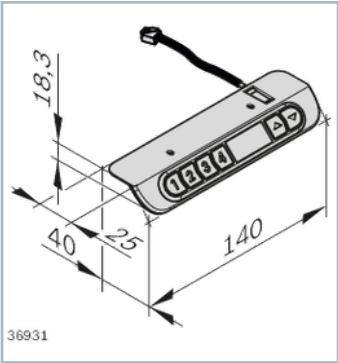

Delivery notes

Scope of delivery

Control unit F1000; EU	Incl. fastening material
Control unit F1600; EU	
Control unit F3200; EU	
Control unit F1000; NA	
Control unit F1600; NA	
Control unit F3200; NA	
Hand switch	

Ordering codes

	Load version	Voltage	No.
	N	V	
Control unit F1000; EU	1000	230 V	3842559921
Control unit F1600; EU	1600	230 V	3842559922
Control unit F3200; EU	3200	230 V	3842559923
Control unit F1000; NA	1000	120 V	3842559931
Control unit F1600; NA	1600	120 V	3842559932
Control unit F3200; NA	3200	120 V	3842559933
Hand switch			3842559940