

niroflex fix

PRODUCTSHEET

niroflex fix hand glove

Colour Code / Size	Weight	Item number
brown: 5 - 5,5 / XXS	0,13 kg	GS 381 000 0000
green: 6 - 6,5 / XS	0,15 kg	GS 381 100 0000
white: 7 - 7,5 / S	0,16 kg	GS 381 110 0000
red: 8 - 8,5 / M	0,17 kg	GS 381 120 0000
blue: 9 - 9,5 / L	0,20 kg	GS 381 130 0000
orange: 10 / XL	0,21 kg	GS 381 140 0000

Material: Stainless steel
 Ring diameter: 4,0 mm
 Wire gauge: 0,50 mm



niroflex fix glove 80 mm cuff

Colour Code / Size	Weight	Item number
brown: 5 - 5,5 / XXS	0,22 kg	GS 381 000 8000
green: 6 - 6,5 / XS	0,24 kg	GS 381 100 8000
white: 7 - 7,5 / S	0,25 kg	GS 381 110 8000
red: 8 - 8,5 / M	0,27 kg	GS 381 120 8000
blue: 9 - 9,5 / L	0,28 kg	GS 381 130 8000
orange: 10 / XL	0,31 kg	GS 381 140 8000

Material: Stainless steel
 Ring diameter: 4,0 mm
 Wire gauge: 0,50 mm



niroflex fix glove 150 mm cuff

Colour Code / Size	Weight	Item number
brown: 5 - 5,5 / XXS	0,26 kg	GS 381 001 5000
green: 6 - 6,5 / XS	0,28 kg	GS 381 101 5000
white: 7 - 7,5 / S	0,29 kg	GS 381 111 5000
red: 8 - 8,5 / M	0,30 kg	GS 381 121 5000
blue: 9 - 9,5 / L	0,34 kg	GS 381 131 5000
orange: 10 / XL	0,35 kg	GS 381 141 5000

Material: Stainless steel
 Ring diameter: 4,0 mm
 Wire gauge: 0,50 mm



DIN EN 1082-1
 ISO 13999-1









niroflex fix

PRODUCTSHEET

■ niroflex fix glove 190 mm cuff

Colour Code / Size Weight Item number







	brown: 5 - 5,5 / XXS	0,3 kg	GS 381 001 9000
	green: 6 - 6,5 / XS	0,32 kg	GS 381 101 9000
	white: 7 - 7,5 / S	0,33 kg	GS 381 111 9000
	red: 8 - 8,5 / M	0,35 kg	GS 381 121 9000
	blue: 9 - 9,5 / L	0,39 kg	GS 381 131 9000
	orange: 10 / XL	0,41 kg	GS 381 141 9000




Material: Stainless steel
 Ring diameter: 4,0 mm
 Wire gauge: 0,50 mm

■ niroflex fix Full arm

Colour Code / Size Weight Item number

	brown: 5 - 5,5 / XXS	0,78 kg	GS 391 000 0000
	green: 6 - 6,5 / XS	0,80 kg	GS 391 100 0000
	white: 7 - 7,5 / S	0,86 kg	GS 391 110 0000
	red: 8 - 8,5 / M	0,94 kg	GS 391 120 0000
	blue: 9 - 9,5 / L	1,02 kg	GS 391 130 0000
	orange: 10 / XL	1,04 kg	GS 391 140 0000

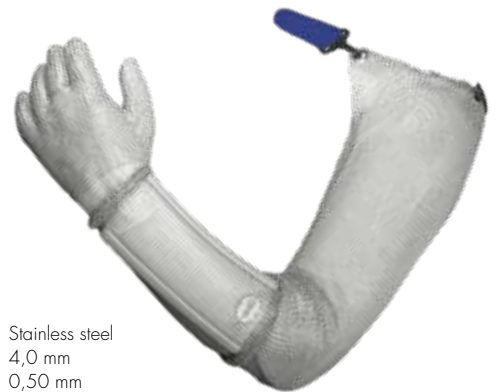

Material: Stainless steel
 Ring diameter: 4,0 mm
 Wire gauge: 0,50 mm