



Sample photo

Order symbol: CAB P 302017
Product nbr: 8104303
Description: Polyester cabinet
Remarks: Grey door

EAN: 6418074050007
El. number:
 Finland 3424133
 Denmark 8212018002
 Sweden 2539817

Including: Cabinet base, door with PUR gasket, 3mm double bit lock(s) with transport and plastic key, screws for mounting plate/DIN-rail and wall fastening lugs with screws. Wall mounting screws not supplied.

Dimensions:	L	W	H
mm:	300	200	170
inch:	11.8	7.9	6.7


Materials:	
Material:	GRP
Base colour:	RAL 7032
Cover colour:	RAL 7032
Cover screws material:	Stainless steel
Gasket material:	Polyurethane

Temperatures:	
Short term:	-50 ... 150 °C
Continuous:	-40 ... 70 °C
Short term:	-60 ... 302 °F
Continuous:	-40 ... 158 °F

Accessories:	
MP 3020	Mounting plate

Rating:
Ingress Protection (EN 60529): IP 66
Impact Resistance (EN 50102): IK 10
Electrical insulation: Totally insulated
UV resistance: UL 508
Flammability Rating (UL 746 C 5): UL 94 5V
Glow Wire Test (IEC 695-2-1) °C: 960
UL Type: UL TYPE 3, 3R, 3S, 4, 4X, 12, 13

Certificates:

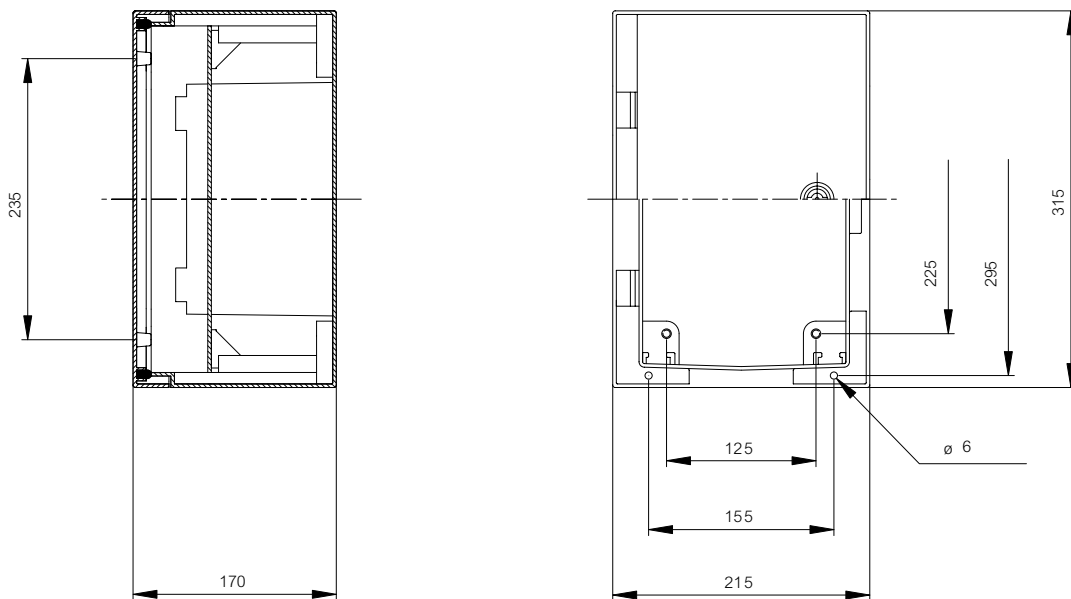

CAB 302017