


NEMIQ[®]
The smart choice

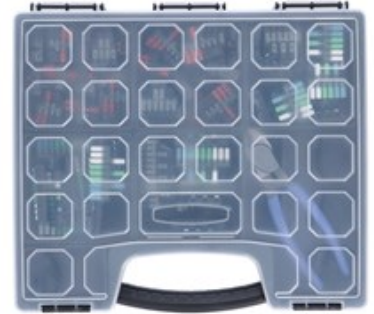

AS SCP80T TL26

E1441417

Assortment Box Branch Connectors, 80pcs, CC 22

Product Properties:

Type of locking/unlocking	Lever
Nominal voltage	450 V
Nominal current	25 A
Suitable for solid conductors	Yes
Transparent	Yes
With operation lever	Yes
Suitable for solid core	Yes
Suitable for flexible core	Yes
Suitable for multi-wire core	Yes
Colour	Multi-coloured

Dimensions:

Max. AWG-size	12
Min. AWG-size	24

Nominal cross section (device side)	0.5-2.5 mm ²
Nominal cross section (installation side)	0.5-2.5 mm ²
Cable diameter	1-4 mm
Conductor cross section flexible (fine-strand) with cable end sleeve	0.5-2.5 mm ²
Conductor cross section solid (solid, stranded)	0.5-2.5 mm ²
Width	315 mm
Height	61 mm
MOQ	1 .
Unit	pcs
Nominal cross section	0.5-2.5 mm ²
Length	315 mm
Nominal voltage	450 V

Approvals:

Compliance:

Other information:

ETIM-Class	EC000446 - Screwless terminal
Trademark	NEMIQ
Product Group	Splicing Connectors - Assortment Boxes
Alternative SKU	ASSCP80TTL26
E-no	E1441417

Logistic information:

Barcode	733117643476
Country of origin	SE
E-no	E1441417
Item status	Stock item, normally in stock with reservation for in between sales.
MOQ	1 .
Stock code	AS SCP80T TL26
Taric code	85369010
Unit	pcs

*We reserve the right to make technical changes and disclaim any typographical errors.