


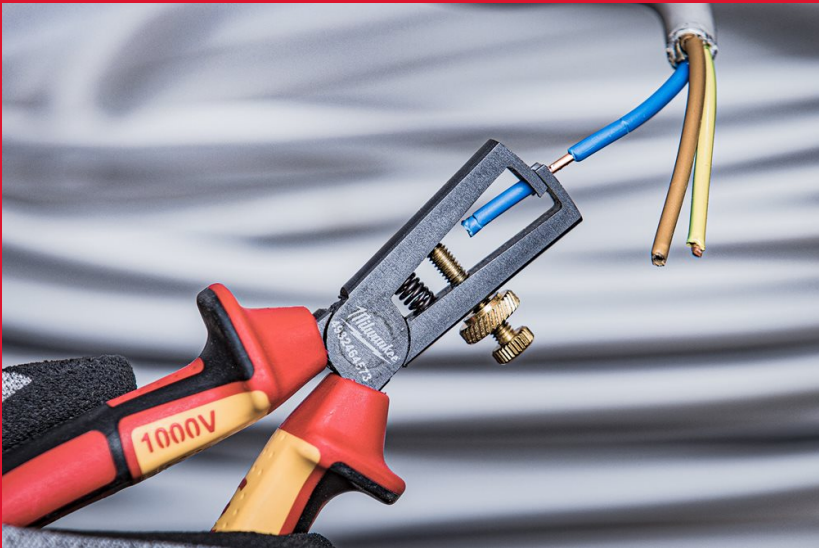

VDE Wire Stripping Plier 160mm

VDE WIRE STRIPPING PLIERS

- VDE (DIN EN/IEC 60900) certified tools. Tested to 10,000 volts and guaranteed to 1,000 volts. Tested against cold to -40°.
- Steel blades are fully forged, hardened and tempered for best durability. Grey titanium surface finish is non reflective and ensures maximum corrosion resistance.
- Induction hardened cutting edges to cut even the hardest of materials.
- Precision machined joint for maximum power transmission with optimum leverage for easy and effortless work.
- Ergonomic grip with softgrip for comfortable handling and good grip.



Article Number	4932464573
Capacity [mm]	-
Capacity Pipe [Max. Ø mm]	-
Cutting capacity in cable Al and Cu [Max. Ø mm]	0.75mm ² - 6mm ²
Cutting capacity in hard wire 1800N/mm ² [Max. Ø mm]	-
Cutting capacity in soft wire 220N/mm ² [Max. Ø mm]	-
Cutting capacity in very hard wire 2300N/mm ² [Max. Ø mm]	-
Length (mm)	160
Pack quantity	1
Total length (mm)	160