



## CROW-FOOT spanner



**540**

Product no. **02200026**  
GTIN **4018754149162**  
Model **540 26**

**Label.** 3/8 " CROW-FOOT spanner Size 26mm L.47mm

**Properties.** • Chrome Alloy Steel, chrome-plated

## Technical drawing.

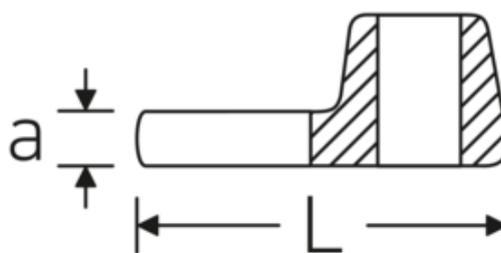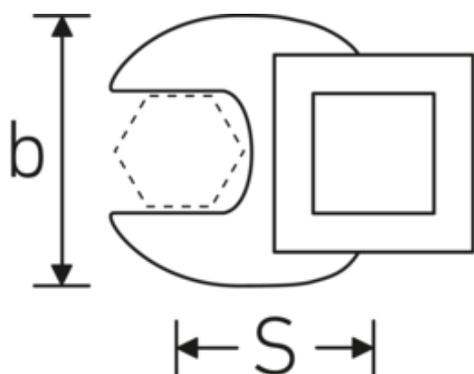

## Technical attributes.

a	8 mm
Square drive inner (inch)	3/8 "
Width mm (b)	45 mm
Length mm (L)	47 mm
S	27,6 mm
Size [mm]	26 mm

## Logistics data.

Depth mm (IFS)	70
Width mm (IFS)	50
Height mm (IFS)	19
WEEE/ElektroG	nicht ear-pflichtig
Length (packaged, mm)	70
Width (packaged, mm)	50
Height (packaging, mm)	19

<b>Volume (packaged, dm3)</b>	0.0665 dm3
<b>Product no.</b>	02200026
<b>Weight (gross, kg)</b>	0,080
<b>Weight PAP (kg)</b>	0,000
<b>Weight PVC (kg)</b>	0,002
<b>GTIN</b>	4018754149162
<b>Country of origin AWR</b>	GERMANY
<b>Region of origin</b>	Nordrhein-Westfalen
<b>Customs tariff no.</b>	82042000
<b>Packing standard</b>	1
<b>Weight (g)</b>	80 g

## Variants.

Product no.	Model No. (ERP)	Description	GTIN
01200008	540 8	1/4 " Crow-foot spanner Size 8mm L.25.5mm	4018754149117
01200009	540 9	1/4 " Crow-foot spanner Size 9mm L.25.5mm	4018754149124
01200010	540 10	1/4 " CROW-FOOT spanner Size 10mm L.25.5mm	4018754149131
02200011	540 11	3/8 " CROW-FOOT spanner Size 11mm L.32mm	4018754149414
02200012	540 12	3/8 " CROW-FOOT spanner Size 12mm L.34.3mm	4018754003495
02200013	540 13	3/8 " CROW-FOOT spanner Size 13mm L.34.3mm	4018754003501
02200014	540 14	3/8 " CROW-FOOT spanner Size 14mm L.37.7mm	4018754003518
02200015	540 15	3/8 " CROW-FOOT spanner Size 15mm L.37.7mm	4018754003525
02200016	540 16	3/8 " CROW-FOOT spanner Size 16mm L.37.7mm	4018754003532
02200017	540 17	3/8 " CROW-FOOT spanner Size 17mm L.42.5mm	4018754003549
02200018	540 18	3/8 " CROW-FOOT spanner Size 18mm L.42.5mm	4018754003556
02200019	540 19	3/8 " CROW-FOOT spanner Size 19mm L.42.5mm	4018754003563
02200020	540 20	3/8 " CROW-FOOT spanner Size 20mm L.42.4mm	4018754141067
02200021	540 21	3/8 " CROW-FOOT spanner Size 21mm L.44.5mm	4018754003570
02200022	540 22	3/8 " CROW-FOOT spanner Size 22mm L.44.5mm	4018754003587
02200023	540 23	3/8 " CROW-FOOT spanner Size 23mm L.44.5mm	4018754141074
02200024	540 24	3/8 " CROW-FOOT spanner Size 24mm L.44.4mm	4018754003594
02200025	540 25	3/8 " CROW-FOOT spanner Size 25mm L.47mm	4018754141081
02200026	540 26	3/8 " CROW-FOOT spanner Size 26mm L.47mm	4018754149162
02200027	540 27	3/8 " CROW-FOOT spanner Size 27mm L.47mm	4018754149179
02200028	540 28	3/8 " CROW-FOOT spanner Size 28mm L.50mm	4018754148806
02200030	540 30	3/8 " CROW-FOOT spanner Size 30mm L.50mm	4018754149186

02200032	540 32	3/8 " CROW-FOOT spanner Size 32mm L.53mm	4018754149193
02200034	540 34	3/8 " CROW-FOOT spanner Size 34mm L.54.5mm	4018754141098
02200036	540 36	3/8 " CROW-FOOT spanner Size 36mm L.56.5mm	4018754141104
02200040	540 40	3/8 " CROW-FOOT spanner Size 40mm L.63mm	4018754141111
02200041	540 41	3/8 " CROW-FOOT spanner Size 41mm L.63mm	4018754141128
02200042	540 42	3/8 " CROW-FOOT spanner Size 42mm L.63mm	4018754141135
02200046	540 46	3/8 " CROW-FOOT spanner Size 46mm L.72mm	4018754141142
02200050	540 50	3/8 " CROW-FOOT spanner Size 50mm L.75mm	4018754141159

## GTIN.



**STAHLWILLE Eduard Wille GmbH**

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal