


Deep groove ball bearings, single row, unsealed



Principal dimensions			Basic load ratings		Fatigue load limit P_u	Speed ratings		Mass	Designation
d	D	B	dynamic	static		Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
12	21	5	1,43	0,67	0,028	70000	43000	0,0063	61801

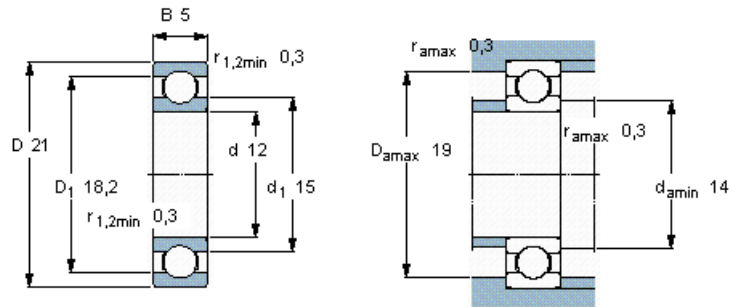

Calculation factors

k_r 0,015

f_0 9,7