

Actuator

45-
2234.11K0.000

Distribution by
Rs-online



<https://rs-online.eao.com/p/45-2234.11K0.000>

Your product:



45-2234.11K0.000 Actuator

FRONT

Front dimension:	Ø 29,5 mm
Front form:	Round
Front bezel colour:	Black
Front bezel material:	Plastic

MOUNTING

Design:	Raised
Mounting cut-out:	Ø 22.3 mm
Mounting type:	Panel mounting

OPERATING-/INDICATION PART

Lens colour:	Colourless
Lens material:	Plastic
Lens illumination:	Illuminated
Lens shape:	Flush
Lens optics:	transparent
Lens type:	Level with front bezel
Illumination colour:	Colourless

MECHANICAL CHARACTERISTIC

Switching action:	Maintained
Switching system:	Slow-make switching element

Mechanical lifetime:	500 000 cycles of operation
Operating frequency:	Max. 1 800/h
Weight:	0.017 kg

AMBIENT CONDITION


IP front protection:	IP66, IP67, IP69K
Operating temperature:	– 25 °C ... + 70 °C
Storage temperature:	– 40 °C ... + 80 °C
Shock resistance:	According to IEC 60068-2-27: Sinusoidal half-wave 50 g / 11 ms
Vibration resistance:	According to IEC 60068-2-6: 20 ... 500 Hz: 5 g
Climate resistance:	During operation according to IEC 60721: 3K6, 3C3, 3S2, 3M6

CERTIFICATE


REACH:	REACH compliant
RoHS:	RoHS compliant

OTHER

Short Description:	Actuator, Ø 22.3 mm, Ø 29,5 mm, Flush, Illuminated, Colourless, Plastic, transparent, Round, Black, Plastic, Maintained, IP66, IP67, IP69K, Colourless
Housing colour:	Black
Housing material:	Plastic
Product attributes:	Push to unlatch
Hints:	Push to unlatch
Wiring diagrams:	

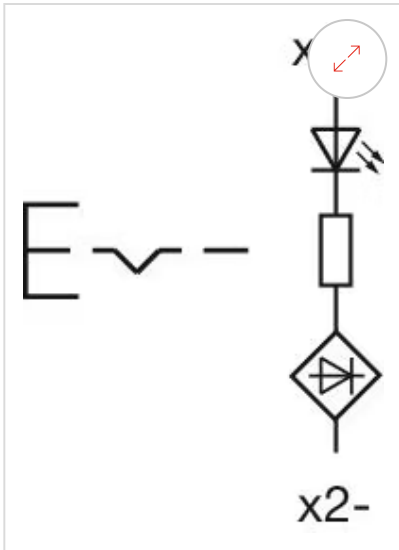

Mounting cut-outs:

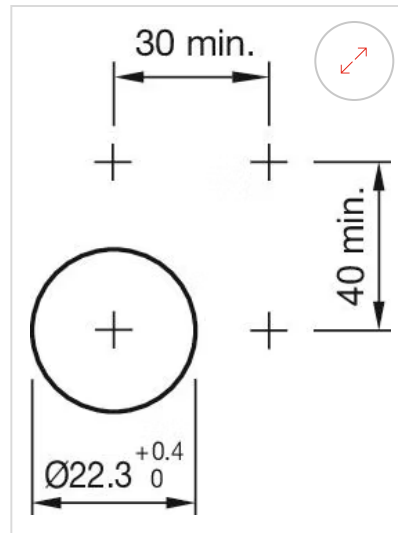

Dimension drawings:

