

---

## 8100

Lamps without halogen, low voltage



---

### Areas of application

- As film projector lamps





# Product datasheet

## Technical data


### Electrical data

Nominal voltage	6.0 V
Lamp wattage	30 W

### Dimensions & weight

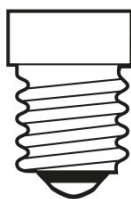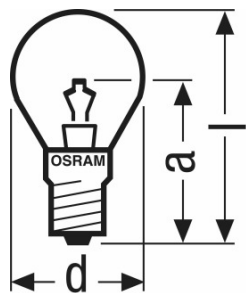

E14  
IEC 7004-23

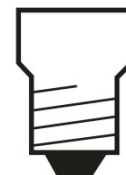

E 14

Diameter	35.0 mm
Light center length (LCL)	35.0 mm
Length	65.0 mm

### Lifespan

Lifespan	600 h
----------	-------

### Additional product data

Base (standard designation)	E14
-----------------------------	-----


### Country specific categorizations

Order reference	8100 5A 6V E14
-----------------	----------------

## Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4050300342122	OSRF8100	-	4739334	-

## Product datasheet

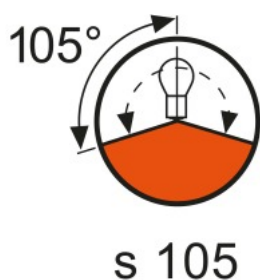

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (height x width x length)	Volume	Gross weight
4050300342122	8100	Folding carton box 1	36 mm x 36 mm x 69 mm	0.09 dm <sup>3</sup>	16.00 g
4050300342139	8100	Shipping carton box 100	191 mm x 166 mm x 366 mm	11.60 dm <sup>3</sup>	1800.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.