


Geberit Mapress Carbon Steel adaptor union with male thread

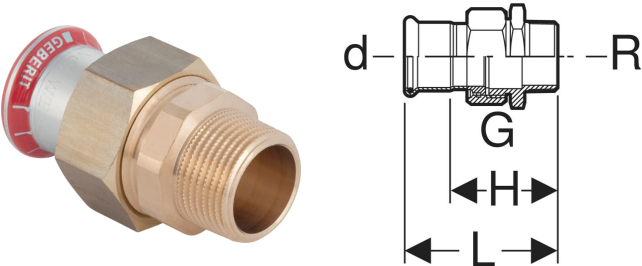

Example image

APPLICATION PURPOSES

- For cooling and heating water without antifreeze agent
- For cooling and heating water with antifreeze agent
- For district heating water ≤ 120 °C
- For extinguishing water (wet)
- For sprinklers (wet)
- For compressed air (oil purity class 3)
- For technical building systems, industry and shipbuilding

CHARACTERISTICS

- Pressing indicator
- Leaky if unpressed
- Outside zinc-plated
- Union nut made of brass
- Adaptor made of gunmetal
- Seal ring made of CIIR, black
- Flat gasket made of EPDM

- Pressing socket with transparent protection plug

TECHNICAL DATA

Medium temperature with flat gasket EPDM	0–100 °C
Product material	Non-alloy steel 1.0034 E195 (EN 10305)

Art. no.	DN	d, ø mm	R "	G "	L cm	H cm
25330	12 / 15	15	1/2	3/4	6.1	4.1
25332	15	18	1/2	3/4	6.1	4.1
25335	20	22	3/4	1	6.8	4.7
25329	20 / 25	22	1	1	6.9	4.8

Art. no.	DN	d _ø mm	R "	G "	L cm	H cm
25337	25	28	1	1 1/4	7.5	5.2
25338	32	35	1 1/4	1 1/2	8	5.4
25339	40	42	1 1/2	1 3/4	8.5	5.5
25340	50	54	2	2 3/8	9.7	6.2