




ENGLISH


## Product Datasheet

# Unscreened multi core coaxial cable,100m

RS Article No: 812-4678

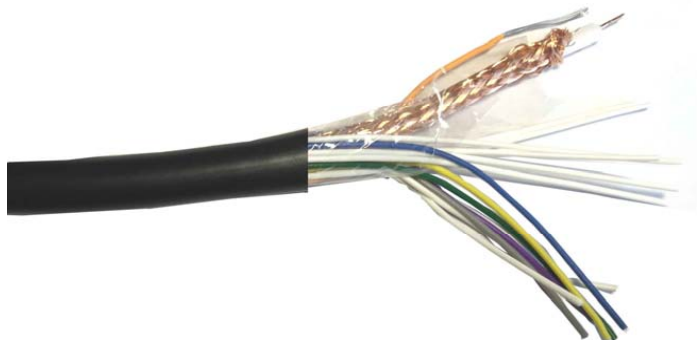

### Cross Section:

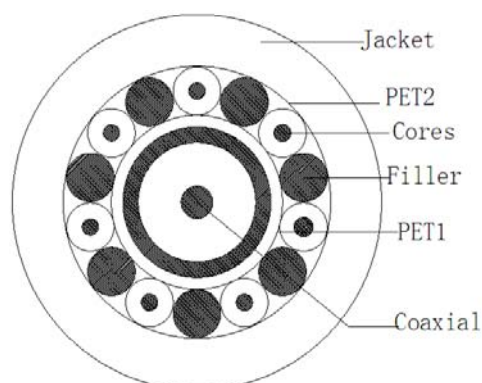

Cable Marking: 7 core + 75  $\Omega$  coaxial cable 001M...100M

Construction:	7C	Coaxial
Conductor:	Strand Tinned Copper	Solid Bare Copper
AWG:	26	22
Structure:	7/0.16	1/0.643
Conductor Dia Nom. (mm):	0.48	0.643
Insulation:	SR-PVC	FM-PE
Average Thickness(mm):	0.26	1.28
Insulation Dia Nom.( $\pm 0.2$ mm):	1.0	3.20
Braid:	-----	Bare Copper
Structure		16/6/0.15
Covrage		93%
PET1		YES
		11

Filler: 7Cx1.0PVC

Assembly: 7C+Coaxial+7C PVC Filler

PET2: YES

Jacket : PVC

Average Thickness(mm): 0.70

Min. Point Thickness(mm): 0.60

Outer Dia Nom.( $\pm 0.50$ mm): 7.80

### Colour:

Coaxial : Nature

PVC filler : White

7C: White, Orange, Yellow, Green, Blue, Violet, Grey

Jacket color: Black

### Electrical Characteristics:

Max. Conductor DC Resistance @20oC (ohms/km): 84

Impedance(OHM): 75+/-3(200MHZ)

Capacitance(PF/M):57(NOM)