




LED FIL G45 E14 DIM 4W (33W) 360lm 827 Opal

Article number: 146934

BAI LED Filament Dimmable Ball G45 E14 4W 2700K Opal 360lm (33W) 230V-240V 320° 45x78mm P45 LED-lamp

LED filament lamps can be seen as the modern sustainable version of the old incandescent lamp. The so-called filaments replace the traditional filament, making the lamps many times more energy-efficient and last much longer. This series of lamps are dimmable (depending on the type of dimmer and the number of lamps to be dimmed on 1 dimmer).

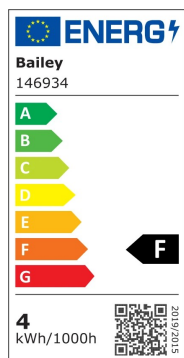

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL G45 E14 DIM 4W (33W) 360lm 827 Opal
Brand	Bailey
Productseries	LED Filament ball
Producttype	G45 E14 827 OP

ETIM specifications

Socket	E14
Luminous flux [lm]	360 - 360
Nominal voltage [V]	220 - 240
Lamp power [W]	4 - 4
Colour temperature [K]	2700 - 2700
Diameter [mm]	45
Length [mm]	78
Dimmable	Yes
Lamp shape	Round/globe
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Opal
Lamp designation	P45
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	360
Power factor	0.9
Lamp efficacy [lm/W]	90
Nominal current [mA]	20 - 20
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Other
Average nominal lifetime [h]	15000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	4
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No
Dimming Zigbee	No

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Glass

Alternative articles



145512

LED Fil P45 E14 DIM 4.5W
(40W) 470lm 827 Softline



80100041654

LED FIL G45 E14 DIM 4W (34W)
380lm 827 Frosted

Complementary articles



142061

Lampholder Metal Screw E14
Chrome



142062

Lampholder Metal Screw E14
Black