

## Y distributor - SAC-3P-M12Y/2XM12FS PE - 1683455

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)

Y-distributor, 3-pos. +PE, straight plug M12 on 2 x straight socket M12




### Why buy this product

- T-plugs
- Termination resistors
- Y-distributors for power and signal connections



### Key commercial data

Packing unit	5 pc
GTIN	 4 017918 166922
Weight per Piece (excluding packing)	28.22 g
Custom tariff number	85366990
Country of origin	Poland

### Technical data

#### Dimensions

Center distance	18 mm
-----------------	-------

#### Ambient conditions

Ambient temperature (operation)	-25 °C ... 90 °C
Degree of protection	IP65
	IP67

#### General

Note	with center distance of 18 mm, suitable for molded connectors and unshielded connectors that can be assembled with QUICKON IDC terminal block connection technology and a connection range of 0.14 mm <sup>2</sup> to 0.34 mm <sup>2</sup>
Rated current at 40°C	4 A
Rated voltage	60 V
Number of positions	3

# Y distributor - SAC-3P-M12Y/2XM12FS PE - 1683455

## Technical data

### General

Contact resistance	≤ 5 mΩ
Insulation resistance	≥ 100 MΩ
Coding	A - standard
Standards/regulations	M12 connector IEC 61076-2-101
Status display	No
Surge voltage category	II
Pollution degree	3
Insertion/withdrawal cycles	≥ 100
Torque	0.4 Nm (M12 connector)

### Material

Inflammability class according to UL 94	HB
Contact material	CuZn
Contact surface material	Ni/Au
Contact carrier material	TPU GF
Material of grip body	TPU, hardly inflammable, self-extinguishing
Material, knurls	Zinc die-cast, nickel-plated
Sealing material	NBR

### Cable

## Classifications

### eCl@ss

eCl@ss 4.0	27060306
eCl@ss 4.1	27060306
eCl@ss 5.0	27061801
eCl@ss 5.1	27061801
eCl@ss 6.0	27061801
eCl@ss 7.0	27061801
eCl@ss 8.0	27061801

### ETIM

ETIM 2.0	EC000830
ETIM 3.0	EC001856
ETIM 4.0	EC002585
ETIM 5.0	EC000830

### UNSPSC

UNSPSC 6.01	31251501
UNSPSC 7.0901	31251501
UNSPSC 11	31251501

# Y distributor - SAC-3P-M12Y/2XM12FS PE - 1683455

## Classifications

### UNSPSC

UNSPSC 12.01	31251501
UNSPSC 13.2	31251501

## Approvals

### Approvals

---

### Approvals

### GOST / GOST

---

 
### Ex Approvals

---

### Approvals submitted

---

## Approval details



## Accessories

### Accessories

### Protective cap

Screw plug - PROT-M12 - 1680539



An M12 screw plug for the unoccupied M12 sockets of the sensor/actuator cable, boxes and flush-type connectors

# Y distributor - SAC-3P-M12Y/2XM12FS PE - 1683455

## Accessories

Sealing cap - PROT-M12 FS - 1560251



M12 sealing cap for unoccupied M12 plugs of the sensor/actuator cable, flush-type plugs and I/O devices in the field

---

## Screwdriver tools

Tool - SAC BIT M12-D15 - 1208432



Nut for assembling sensor/actuator cables with M12 connector and for M12 connectors with QUICKON fast connection technology, for 4 mm hexagonal drive

---

## Torque tool

Torque screwdriver - TSD 04 SAC - 1208429




Torque screwdriver, with preset torque of 0.4 Nm and 4 mm hexagonal drive for M12 connectors

---


## Drawings

Schematic diagram

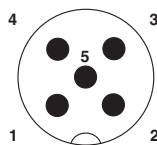

Pin assignment M12 male connector, 5-pos., A-coded, male side


Schematic diagram

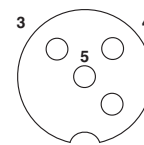

Pin assignment socket M 12, 3-pos. + PE


# Y distributor - SAC-3P-M12Y/2XM12FS PE - 1683455

Dimensioned drawing

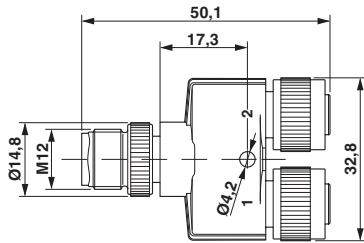


Plug M12 x 1, Y distributor

Circuit diagram

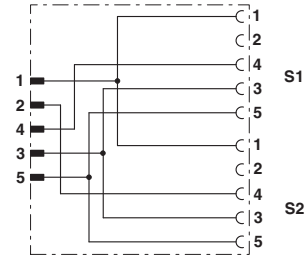

Contact assignment of the M12 Y distributor

Schematic diagram

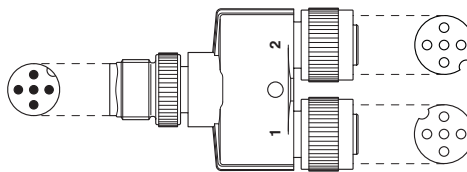

Layout of connector pin assignments