



Brushed Chrome




White

HAND DRYERS



Available in white or brushed chrome, our range of automatic hand dryers provide a cost effective and hygienic means of non-touch hand drying. Suitable for public amenities, food prep areas, hospitals and schools.

- Available in white epoxy paint or brushed chrome finish.
- Automatic infrared on/off activation.
- 360° nozzle rotation to provide face or hand drying.
- Drying cycle of approximately 15 seconds.
- Self-resetting thermal overload protection.
- Automatic cut-off after 60 seconds of continuous use.
- 220-240V, single-phase, 50Hz.

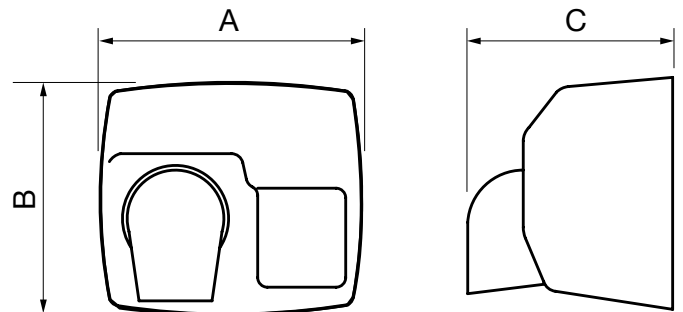

MODEL NO.	STYLE	A	B	C
HHD2500RB	Brushed Chrome	270	240	212
HHD2500RW	White	270	240	212

All dimensions in mm

MODEL NO.	M ³ /HR	L/SEC	FAN SPEED, RPM	AVG. dB(A) @1M	WEIGHT KG**
HHD2500RB	270	75	8300	74	6.3
HHD2500RW	270	75	8300	74	6.3

**Refers to weight (kg)

