

#4131 - 2 Core Flat Loudspeaker Cable 2.5mm2



Part NO: #4131

Product Code: RGW-1883

Product Description

Reference Standard

Customer's sample spec.and the general standard

Multi-construction

2Cores

Cable Construction

Conductor

Bare Copper

Construction

$0.1 \pm 0.008 \times 46 \times 7$

Standard Dia.(mm)

2.4

Insulation

Trans PVC

Thickness

0.55

Insulation Dia.(mm)

$3.5 \pm 0.1 \times 2C$

Insulation Color

Trans PVC

Marking

Colour Stripe (Black) on one side for identification


PACKAGING

100M/Reel

Revision History

A0-1

Design

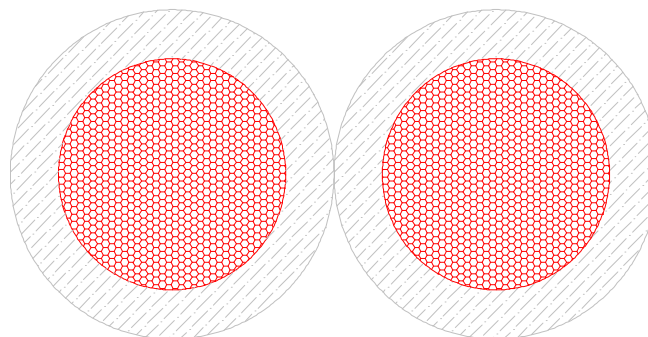

A: Electrical Characteristics

Max.Conductor DC Resistance at 20°C (Ω /Km) <7.36

Min.Insulation DC Resistance at 20°C ($M\Omega$ *Km) >200

Rated Temperature(°C) 80

Rated Voltage (V) 300

RoHS GUIDELINE

We operate according to the following standards

Control Item	Standard	Testing Method	Testing Equipment
Cadmium content (Cd)	<0.01%	EN1122	ICP-AES
Lead content (Pb)	<0.1%	EPA3050B	ICP-AES
Mercury content (Hg)	<0.1%	EPA3052	ICP-AES
Chromium (VI) content	<0.1%	EPA3060(UN-VIS)	ICP-AES
Polybrominated Biphenyls(PBB)	Forbidden	GC/MS	
Polybrominated Diphenyl Ether (PBDE)	Forbidden	GC/MC	

Date: 2013-03-06

Page: 1 / 1