


WIRE ROUTING, CLIPS AND CLAMPS

E

Part No.	"A" mm	"B" mm	"C" mm	RMS
CFCC-3-05A-RT	14.3	12.4	4.6	05
CFCC-4-05A-RT	14.3	10.2	6.4	
CFCC-8-05A-RT	27.0	22.4	6.4	
CFCC-8-04A-RT	27.0	22.4	6.4	04

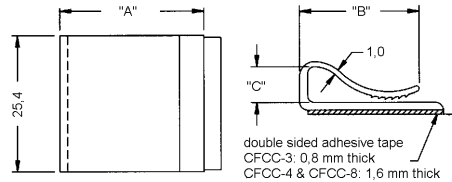

Material: Noryl - white, UL 94 V-1, RMS-05
or
Rigid PVC - grey, UL 94 V-0, RMS-04
Adh. Tape: Working temperature -20°C – +50°C
Std. Pk.: 1.000 pcs.



CFCC

C-TYPE FLAT CABLE CLAMP

Note:

CFCC	3	05	A-RT
Part	Size	Material Code	with Tape