




AMP

TE Internal #: 1424050-1

Premium Crimp Tooling, Removable/Interchangeable, TE Product Specification (114-), Battery / Electric / Manual, Hand Crimping Tools

[View on TE.com >](#)

Application Tooling > Hand Crimping Tools

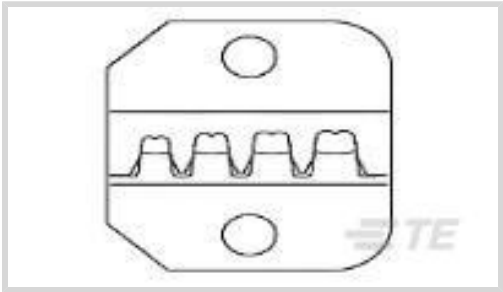

Tool Grade: Premium Crimp Tooling

Die Sets Type: Removable/Interchangeable

Specification Type: TE Product Specification (114-)

TE Certification: Upon Request for Fee

Power Technology Type: Battery, Electric, Manual, Pneumatic

Features

Other

Crimp Form-Wire Barrel Type	Closed Barrel - COAX
Tool Grade	Premium Crimp Tooling
Die Sets Type	Removable/Interchangeable
Specification Type	TE Product Specification (114-)
TE Certification	Upon Request for Fee
Power Technology Type	Battery, Electric, Manual, Pneumatic
Tooling Type	Standard Die Envelope (SDE) Die Set

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Out of Scope
EU ELV Directive 2000/53/EC	Out of Scope
China RoHS 2 Directive MIIT Order No 32, 2016	Not reviewed for China RoHS compliance
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2021 (211) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free









Solder Process Capability


Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

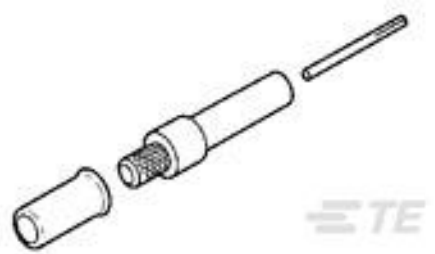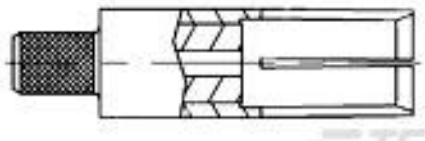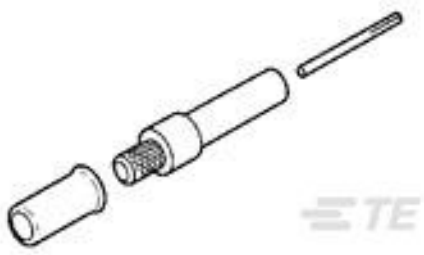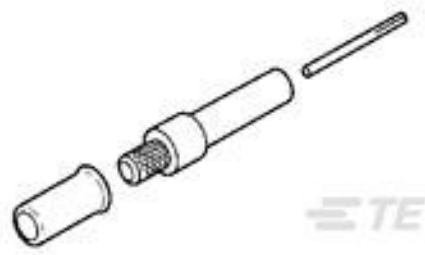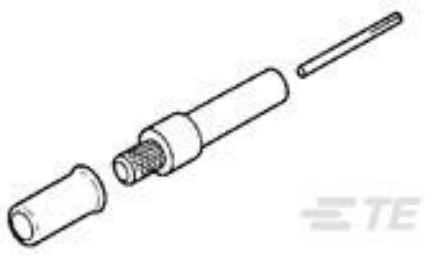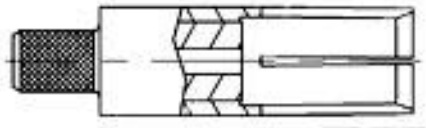
 TE Part # 225790-9 COAXIAL, RF, PIN, SZ 5, ARINC	 TE Part # 2-331351-4 BNC JACK, PTFE	 TE Part # 225791-2 COAXIAL RF SOCKET, SZ 5	 TE Part # 5225396-7 BNC JACK DUAL CP RG174,188
 TE Part # 8-331350-0 BNC PLUG PTFE	 TE Part # 225790-1 ARINC PIN SIZE 5	 TE Part # 225790-4 ARINC COAXICON PIN SIZE 5	 TE Part # 225790-7 ARINC PIN SIZE 5
 TE Part # 225791-4 ARINC SIZE 5 SOCKET	 TE Part # 2-331350-4 BNC PLUG, PTFE	 TE Part # 5225398-7 BNC DUAL CRIMP JACJ	 TE Part # 9-331350-3 BNC PLUG PTFE

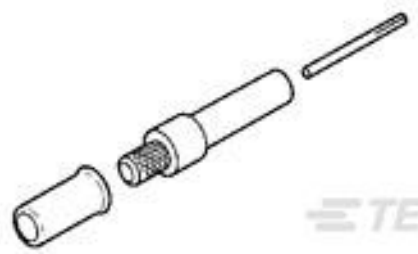


TE Part # 225790-5
ARINC COAXICON PIN SIZE 5




TE Part # 1-5227079-6
COMM BNC PLUG

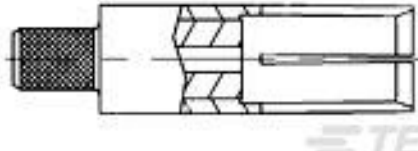

TE Part # 225791-3
ARINC COAXICON SOCKET SIZE 5

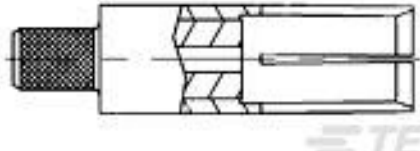

TE Part # 225791-8
ARINC - SKT SIZE 5

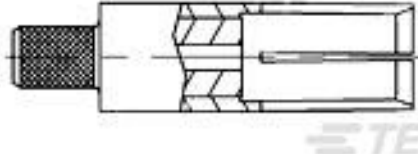

TE Part # 225791-1
KIT,ARINC SOCKET,SIZE 5




TE Part # 5225395-8
BNC PLUG DUAL CRIMP RG179, 187

Customers Also Bought



TE Part #1546670-2
2P .437" DR BARRIER,W/BND SCRW

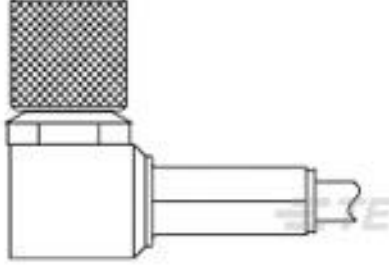

TE Part #1467950-1
132-0116-0002




TE Part #1838276-2
M12 Plas Fld Ser CONN. Female Skt Sldr



TE Part #NB-PTCO-005
Pt100, 2.0x2.3, Class C, PTFC101C1G0 Sldr




TE Part #5745175-2
CABLE CLAMP KIT,SZ 5

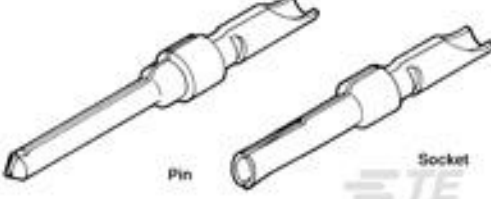


TE Part #66569-2
20DF SOCKET,PLATED



 
TE Part #1466294-1
03300010001



TE Part #2-1532006-8
142-0000-0002=PLUG,STRAIGHTS-

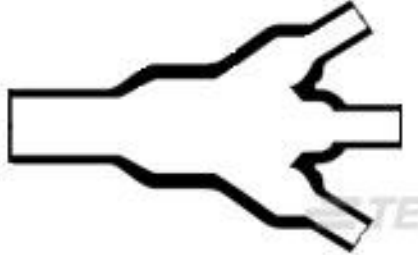

TE Part #820055-000
462A011-25-0

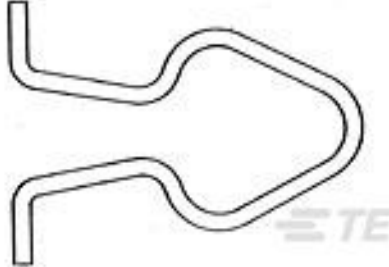

TE Part #552100-1
CLIP, BAIL

Documents



Datasheets & Catalog Pages

Bottoming Dies

English

Instruction Sheets

Instruction Sheet (U.S.)

English