

Caps to Holder FEC



500 VAC · 4 W/10 A (VDE) · 600 VAC/DC · 20 A (UL/CSA)



Standards

- IEC 60127-6
- UL 4248-1
- CSA C22.2 no. 4248.1

Approvals

- VDE Certificate Number: 137910 UG
- UL File Number: E39328

References

Mating Cap to [FEC](#)

Weblinks


[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [REACH](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Detailed request for product](#)

Technical Data

| | |
|------------------------------|------------------------------------|
| Fuse-Link | 5 x 20 or 6.3 x 32 mm |
| Rated Voltage | 500 VAC (VDE), 600 VAC/DC (UL/CSA) |
| Rated current | 10 A (VDE), 20 A (UL/CSA) |
| Rated Power Acceptance IEC | 4 W / 10 A @ Ta 23 °C |
| Degree of Protection | IP 40 |
| Admissible Ambient Air Temp. | -40 °C to 85 °C |
| Material: Cap | Thermoset |
| Storage Conditions | 0 °C to 60 °C, max. 70% r.h. |

| | |
|--------------------|---------------|
| Contact Resistance | < mΩ at 20 mV |
|--------------------|---------------|

Dimension

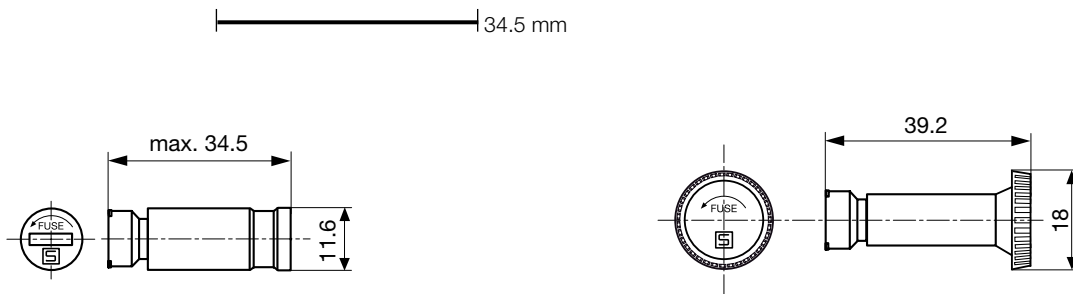

All Variants

| Cap | Fuse-Link | Degree of Protection | Order Number |
|------------|------------|----------------------|--------------|
| slotted | 5 x 20mm | IP 40 | 0031.1611 |
| slotted | 6.3 x 32mm | IP 40 | 0031.1613 |
| Fingergrip | 6.3 x 32mm | IP 40 | 0031.1616 |

Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/Stock-Check/Stock-Check-SCHURTER>

Packaging Unit

Plastic Bag (100 pcs.)