



Excellent 27" WQHD monitor for business usage and occasional gaming

The features of the 27" monitor combines both business and gaming features, so choosing your next display need not be an agonising choice. The IPS panel technology offers accurate and consistent colour reproduction with wide viewing angles. The ergonomic stand enables 13cm height adjustment and rotation making this screen suitable for applications and environments where workplace flexibility and ergonomics are key factors. Gamers, in turn, will appreciate 1ms MPRT, FreeSync and Black Tuner features.



IPS Technology

IPS displays are best known for wide viewing angles and natural, highly accurate colours. They are especially suited for colour-critical applications.



WQHD

With true WQHD 2560 x 1440p resolution your monitor is ready to display high definition images. This means you can accommodate more information on your screen, i.e. over 76% more in comparison to a 1920 x 1080 monitor.

01 DISPLAY CHARACTERISTICS

Design	ultra slim
Diagonal	27", 68.5cm
Panel	IPS LED, matte finish
Native resolution	2560 x 1440 @75Hz (3.7 megapixel)
Aspect ratio	16:9
Panel brightness	250 cd/m ²
Static contrast	1000:1
Advanced contrast	80M:1
Response time (MPRT)	1ms
Viewing zone	horizontal/vertical: 178°/178°, right/left: 89°/89°, up/down: 89°/89°
Colour support	16.7mln
Horizontal Sync	31 - 120kHz
Viewable area W x H	596.7 x 335.7mm, 23.5 x 13.2"
Pixel pitch	0.233mm
Colour	matte, black

02 INTERFACES / CONNECTORS / CONTROLS

Signal input	HDMI x1 DisplayPort x1
USB HUB	x2 (v.2.0 DC5V, 500mA)
HDCP	yes
Headphone connector	yes

03 FEATURES

Blue light reducer	yes
Flicker free	yes
FreeSync support	yes
OSD languages	EN, DE, FR, ES, IT, RU, JP, CZ, NL, PL
Control buttons	Power, Menu, Scroll Up / i-Style Colour, Scroll Down / Input Select, Left / ECO, Right / Volume
User controls	picture adjust (contrast, brightness, OD, AC, ECO, blue light reducer, black tuner, colour saturation, gamma), input select (input source), audio settings (volume, mute), store user settings, colour settings (colour temperature, user preset), language, setup menu (OSD H. position, OSD V. position, OSD time, opening logo, AMD FreeSync, MBR), display information, recall
Speakers	2 x 2W
Convenience	Kensington-lock™ prepared, DDC2B

04 MECHANICAL

Display position adjustments	height, pivot (rotation), tilt
Height adjustment	130mm
Rotation (PIVOT function)	90°
Tilt angle	18° up; 3° down
VESA mounting	100 x 100mm
Cable management system	yes

05 ACCESSORIES INCLUDED

Cables	power, USB, HDMI, DP
Other	quick start guide, safety guide

06 POWER MANAGEMENT


Power supply unit	internal
Power supply	AC 100 - 240V, 50/60Hz
Power usage	23W typical, 0.5W stand by, 0.5W off mode

07 SUSTAINABILITY

Regulations	CE, TÜV-Bauart, EAC, PSE, RoHS support, ErP, WEEE, VCCI, REACH, ENERGY STAR®
Energy efficiency class (Regulation (EU) 2017/1369)	F
REACH SVHC	above 0.1%: Lead

08 DIMENSIONS / WEIGHT

Product dimensions W x H x D	611.5 x 414.5 (544.5) x 256mm
Box dimensions W x H x D	694 x 480 x 227mm
Weight (without box)	5.4kg
Weight (with box)	9.6kg
EAN code	4948570117994

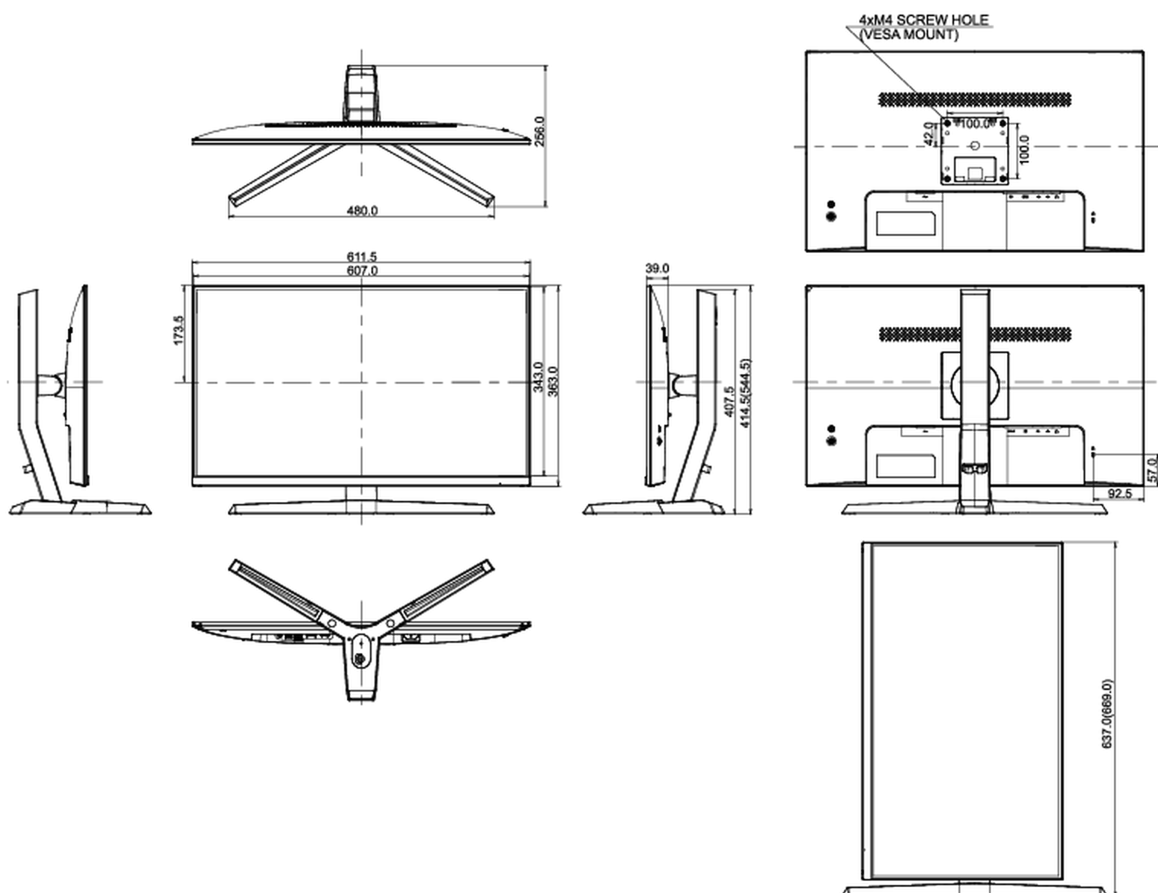

All trademarks and registered trademarks acknowledged. E & O E. Specification subject to change without notice. All LCD's comply with ISO-9241-307:2008 in connection with pixel defects.

© IIYAMA CORPORATION. ALL RIGHTS RESERVED