



Sample photo

Order symbol: CAB P 1008030
Product nbr: 8104309
Description: Polyester cabinet
Remarks: Grey door

EAN: 6418074050069
El. number:
 Finland 3424145
 Denmark 8212018060
 Sweden 2539829

Including: Cabinet base, door with PUR gasket, 3mm double bit lock(s) with transport and plastic key, screws for mounting plate/DIN-rail and wall fastening lugs with screws. Wall mounting screws not supplied.

Dimensions:	L	W	H
mm:	1000	800	300
inch:	39.4	31.5	11.8


Materials:	
Material:	GRP
Base colour:	RAL 7032
Cover colour:	RAL 7032
Cover screws material:	Stainless steel
Gasket material:	Polyurethane

Temperatures:	
Short term:	-50 ... 150 °C
Continuous:	-40 ... 70 °C
Short term:	-60 ... 302 °F
Continuous:	-40 ... 158 °F

Accessories:	
MP 10080	Mounting plate

Rating:
Ingress Protection (EN 60529): IP 66
Impact Resistance (EN 50102): IK 10
Electrical insulation: Totally insulated
UV resistance: UL 508
Flammability Rating (UL 746 C 5): UL 94 5V
Glow Wire Test (IEC 695-2-1) °C: 960
UL Type: UL TYPE 3, 3R, 3S, 4, 4X, 12, 13

Certificates:

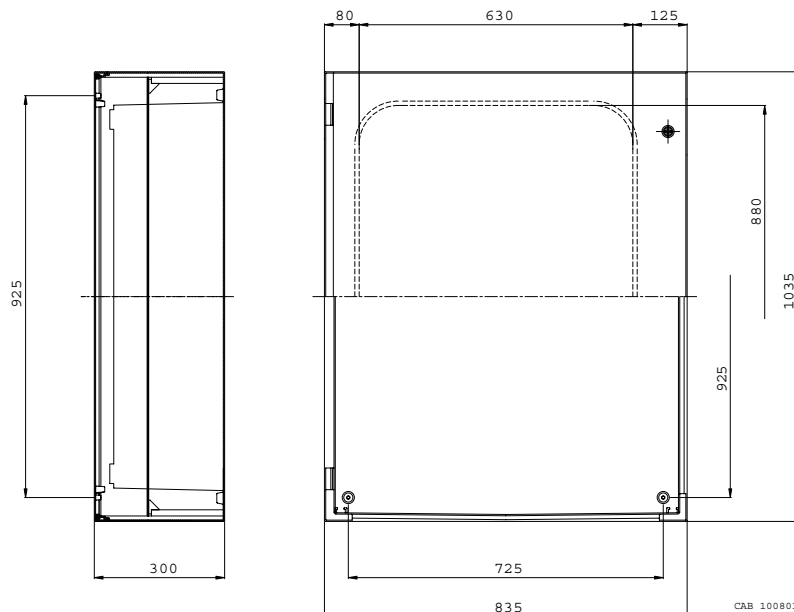

CAB 1008030