



SENTRON, cylindrical fuse holder, 10x38 mm, 1P+N, In: 32 A, Un AC: 690 V

Model	
product brand name	SENTRON
product designation	Cylindrical fuse holder
General technical data	
number of poles	2
design of pole	1P+N
size of fuse link	10 x 38 mm
Supply voltage	
operating voltage	
• at AC rated value	690 V
protection class IP	IP20
Mechanical Design	
height	81 mm
width	18 mm
depth	64 mm
Net Weight	77 g
Certificates	
reference code according to IEC 81346-2	F

Approvals Certificates

Environment	General Product Approval
-------------	--------------------------

[Environmental Confirmations](#)



[Confirmation](#)



Test Certificates	other
-------------------	-------

[Miscellaneous](#)



[Confirmation](#)

Further information

- Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
- Information for data generation and storage
<https://support.industry.siemens.com/cs/ww/en/view/109995012>
- Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW7053>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW7053>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

https://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NW7053

CAX-Online-Generator


<https://www.siemens.com/cax>


Tender specifications

<https://www.siemens.com/specifications>

Characteristic curves

https://curves.simarisiemens.com/curves/<mmp_prod_noCOMP='HAUPT'></mmp_prod_no>

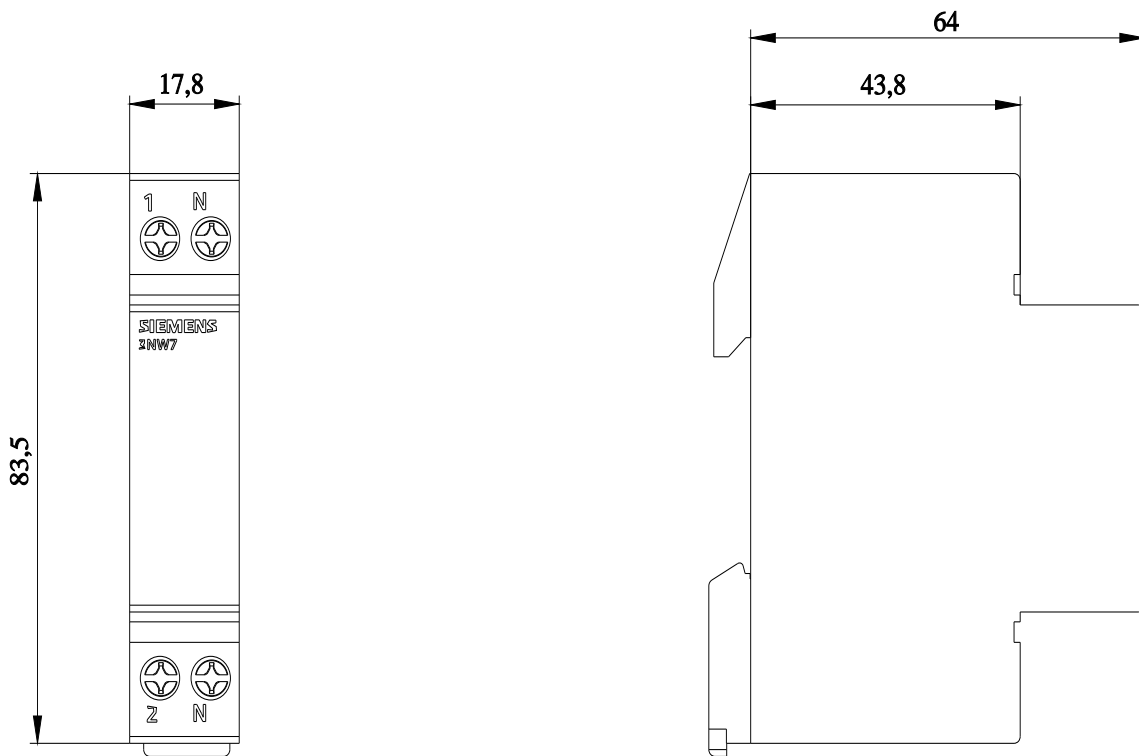

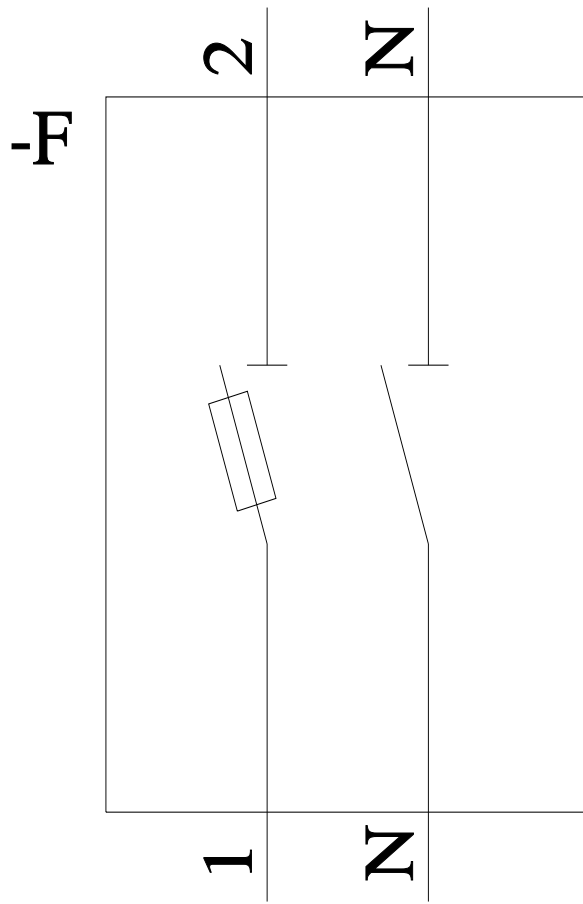

last modified:

4/6/2025 