


Electronics module VMPA-MPM-EMM-P5

Part number: 8111881

FESTO

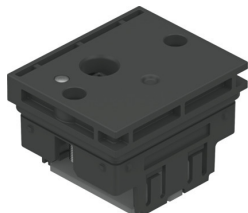

 [General operating condition](#)

Data sheet

Feature	Value
Max. number of valve positions	1
Max. number of valve coils	1
Reverse polarity protection	yes
Additional functions	For soft-start valve
Operating voltage DC load voltage	21.6 V ... 26.4 V
Nominal pick-up current per solenoid coil	60 mA to 30 ms
Nominal current with current reduction	22 mA after 30 ms
Isolation channel - internal bus	no
Corrosion resistance class CRC	1 - Low corrosion stress (when installed)
LABS (PWIS) conformity	VDMA24364 zone III
Ambient temperature	-5 °C ... 50 °C
Product weight	20 g
Electrical control	Multi-pin plug
Material housing	POM
Note on materials	RoHS-compliant