

## CRIMPING TOOLS

for non insulated cable connections

### K 93

with ratchet.  
For tubular cable lugs  
and connectors,  
for solid conductors,  
hexagonal crimping.

range: 1.5 – 4 mm<sup>2</sup>  
length: approx. ca. 220 mm  
weight: approx. ca. 0.560 kg



### K 23/2

with ratchet.  
For tubular cable lugs  
and connectors,  
for terminals DIN 46234  
and pin terminals DIN 46230.  
Indent crimping.

range: 0.75 – 2.5 mm<sup>2</sup>  
length: approx. 220 mm  
weight: approx. 0.550 kg



### K 94

similar to K 93

range: 6 – 10 mm<sup>2</sup>  
length: approx. ca. 220 mm  
weight: approx. ca. 0.560 kg

### K 24/2


similar to K 23/2

range: 4 – 10 mm<sup>2</sup>  
length: approx. 220 mm  
weight: approx. 0.550 kg

### K 13

for tubular cable lugs  
and connectors,  
for terminals DIN 46234  
and pin terminals DIN 46230.  
With stripper from 0.5 to 6 mm<sup>2</sup>  
and cutter for screws M 2.6 – M 5  
and wire cutter.  
Indent crimping.

range: 0.5 – 6 mm<sup>2</sup>  
length: approx. 210 mm  
weight: approx. 0.230 kg

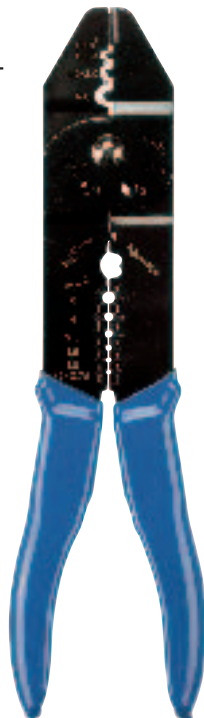

### K 2

with ratchet.  
For tubular cable lugs  
and connectors "standard type".  
Indent crimping.

range: 0.75 – 16 mm<sup>2</sup>  
length: approx. 325 mm  
weight: approx. 0.600 kg

