



Brand of NTN corporation


Technical data

BBER25UU

Flange type ball bushings



VISUAL (S)

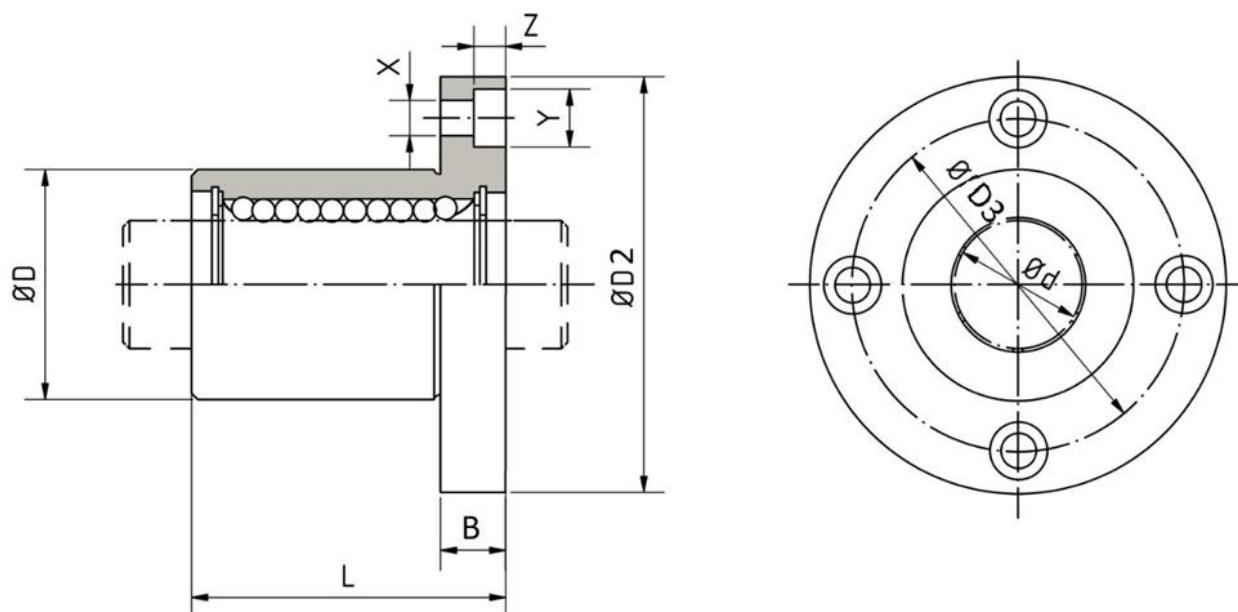

PRODUCT DEFINITION

Brand	SNR
Design type	BBER
Ball bushings category	Flange type ball bushings
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	25 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0,011/-0,001
D - External diameter	40 mm
D - External diameter tolerance	0/-0,019
L - Length	58 mm
L - Length tolerance	0,3/-0,3
B - Flange width	8 mm
D2 - Diameter	62 mm
D3 - Diameter	51 mm
X	5,5 mm
Y	9 mm
Z	5,1 mm
Maximum eccentricity	0,015 mm
Number of ball rows	6
Mass	0,335 kg

PRODUCT PERFORMANCE	
Cmin	0,908 kN
Cmax	1,162 kN
C0min	1,57 kN
C0max	2,01 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BBER25UU



ESHOPDONOTDISPLAY	
Image	BBER_1.JPG, BBER_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes
Tracepart	Oui/Yes

