


Mounting plate VABA-B14-FL12-FL14

Part number: 8098889

FESTO

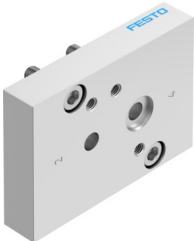

 [General operating condition](#)

Data sheet

Feature	Value
Mounting position	optional
Operating pressure	1.5 bar ... 10 bar
Operating medium	Compressed air to ISO 8573-1:2010 [7:-:-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-20 °C ... 60 °C
Media temperature	-20 °C ... 60 °C
Ambient temperature	-20 °C ... 60 °C
Product weight	188 g
Type of mounting	With through-hole
Pneumatic connection, port 2	Flange 1/4 with NAMUR port pattern Flange 1/2 with NAMUR port pattern
Pneumatic connection, port 4	Flange 1/4 with NAMUR port pattern Flange 1/2 with NAMUR connection pattern
Note on materials	RoHS-compliant
Material sub-base	Wrought aluminium alloy