

# ABS H 95 G



Sample image

**Order symbol :** ABS H 95 G

**Product nr :** 8784315

**Description :** Enclosure, ABS



**Remarks :** Grey cover

**EAN :** 6418074002297

**El. number :**

- Finland : 3423467
- Denmark : 8212001970
- Sweden : 2536726

**Including :** Base with screws for mounting plate/DIN-rail. cover with PUR gasket and polyamide cover screws.

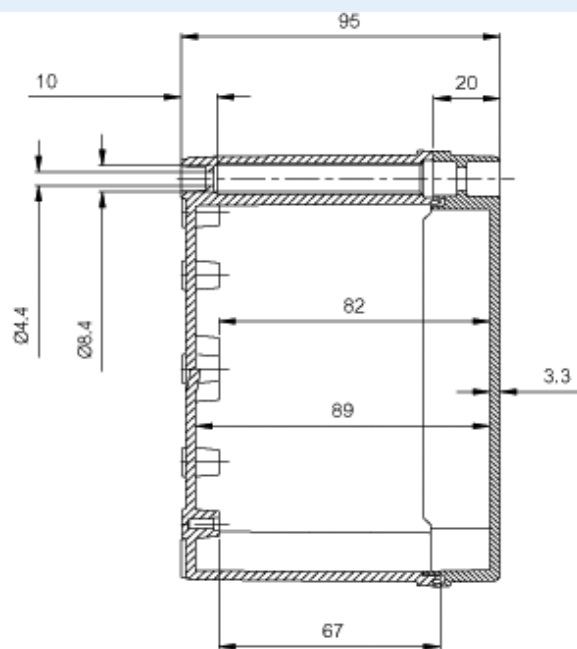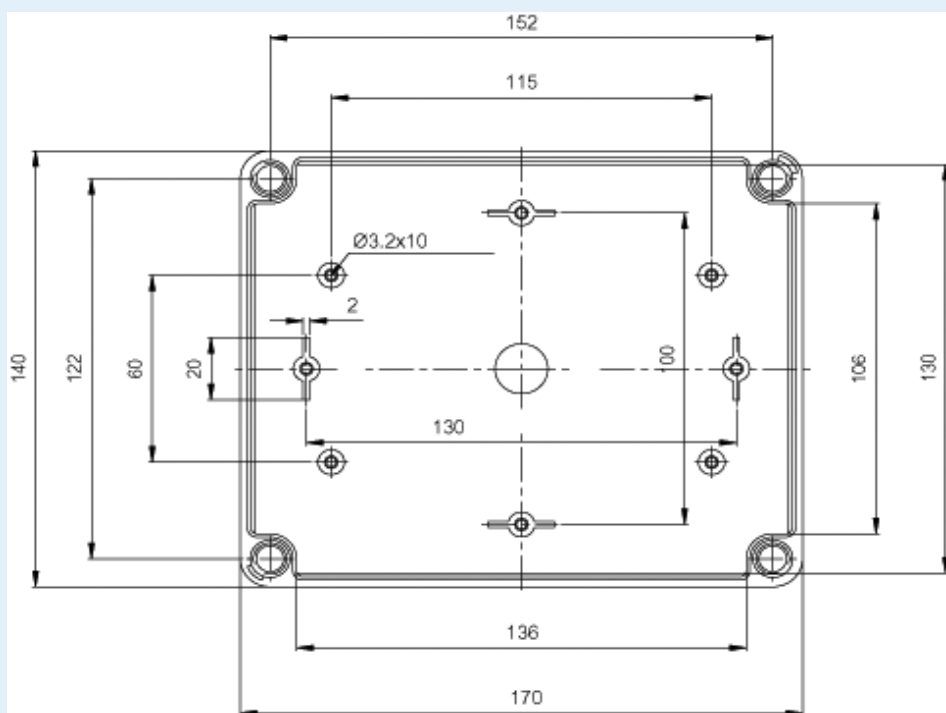

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm :         | 170    | 140   | 95    |
| inch :       | 6.69   | 5.51  | 3.74  |

## Materials :

|               |          |
|---------------|----------|
| Material :    | ABS      |
| Base colour : | RAL_7035 |

## Accessories :

|          |                                                         |
|----------|---------------------------------------------------------|
| CHM-3    | DIN-35 Mounting rail, for enclosures:<br>(110 x 35 x 7) |
| FP 22046 | Wall fastening lug (4 pcs)<br>(35 x 16 x 10)            |
| DH-3     | DIN-35 Mounting rail, for enclosures:<br>(140 x 35 x 7) |
| H-MP     | Mounting plate, for enclosures:<br>(125 x 94 x 1.5)     |

|                   |                      |
|-------------------|----------------------|
| Cover colour :    | RAL 7035 -light grey |
| Gasket material : | Polyurethane         |

|                               |             |
|-------------------------------|-------------|
| <b>Temperatures :</b>         |             |
| Temperature °C (continuous) : | -40 ... 60  |
| Temperature °F (continuous) : | -40 ... 140 |

|                                         |                   |
|-----------------------------------------|-------------------|
| <b>Ratings :</b>                        |                   |
| Ingress protection (EN 60529):          | IP66; IP67;       |
| Impact Resistance (EN 62262):           | IK08;             |
| electrical_insulation :                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes               |
| UV resistance :                         | -                 |
| Flammability Rating :                   | UL 94 HB          |
| Glow Wire Test (IEC 695-2-1) °C :       | 650C              |

|                       |  |
|-----------------------|--|
| <b>Certificates :</b> |  |
| SGSFIMKO_PICC_pc      |  |