


Features

- 1.5 mm pitch
- Voltage Rating:100V
- Current Rating:1.0A
- Low Mating Force
- Reliable contact
- 6 Way Top Entry PCB Header

RS PRO 1.5MM HEADER TOP ENTRY 06WAY

RS Stock No.: 0147048

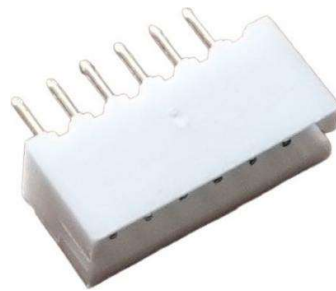

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- These 1.5 mm pitch Shrouded Headers are Top Entry, through Hole mounting types. The PC Board thickness for these 1.5 mm pitch vertical Headers can range from 0.6 to 1.2 mm.
- Contact material is brass

General Specifications

Number of Contacts	6
Number of Rows	1
Body Orientation	Straight
Dimensions(mm) A:	7.5
Dimensions(mm) B:	10.5
Termination Method	Solder
Contact Material	Brass
Contact Plating	Tin plating
Insulator	Nylon 66, UL94V-0
Colour	White

Electrical Specifications

Voltage Rating	100V AC,DC
Current Rating	1A, AC, DC
Insulation Resistance	500M ohm min
Withstanding Voltage	500V AC/minute

Mechanical Specifications

Mounting Type	Through Hole
Pitch	1.5 mm
Pin size	0.5mm
Pin height	2.8mm

Operation Environment Specifications

Operating Temperature	-40°C to 105°C
-----------------------	----------------

Approvals

Compliance/Certifications	RoHS Compliant
Declarations	Reach

Spec Drawings

