


Part Number: 1905X3ZX

Type	Size	Rating	Description
LED	M8	24VAC/DC	Recessed Bezel Panel Indicator

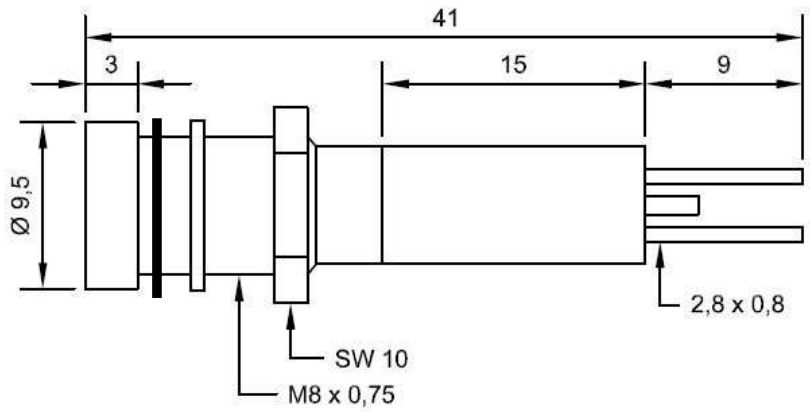

Part #	Colour	Current (mA)	Intensity (mcd)
1905X3Z3	Red	9/18	80
1905X3Z1	Green	9/18	32
1905X3Z2	Yellow	9/18	32
1905X3Z7	Blue	9/18	60

Notes:

- 1 X = Chrome Bezel finish. 0 = Satin, 1 = Black, 2 = Matt
- 2 Electrical & optical data are measured at an ambient temperature of 25°C
- 3 Luminous intensity at DC
- 4 Storage temperature -25 °C to +80°C
- 5 Application temperature -20 °C to +60°C
- 6 Voltage tolerance ±10%
- 7 Due to component tolerances, colour temperature variations may be observed
- 8 The terminals are not qualified for soldering
- 9 Degree of protection IP67 when used with the supplied gasket
- 10 The plastic(polycarbonate) has limited chemical resistance
- 11 RoHS & REACH SVHC compliant