


Product datasheet

Specifications

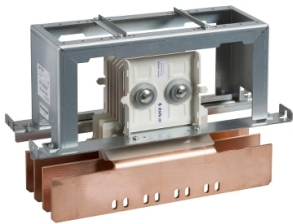

CANALIS INTERFACE 1600A 4P

LVS04704

EAN Code: 3606481868121

Main

Range	PrismaSeT
Range of product	PrismaSeT P
Product or component type	Interface and connection Canalis
product name	PrismaSeT PrismaSeT P enclosure
Accessory / separate part category	Interface accessory
Standards	IEC 61439-2, inside enclosure IEC 61439-1, inside enclosure
Product certifications	ASTA

Complementary

Cubicle-device connection	KT with Canalis
Poles description	4P
installation description	Cubicle - width 650 mm
Cubicle depth	400 mm: front 400 + 400 mm: rear
Installed device	ComPact: drawout NS630b...1000 - control: direct front rotary handle vertical installation ComPact: drawout NS1250 - control: direct front rotary handle vertical installation ComPact: drawout NS630b...1000 - control: motor mechanism vertical installation ComPact: drawout NS1250 - control: motor mechanism vertical installation ComPact: drawout NS630b...1000 - control: toggle vertical installation ComPact: drawout NS1250 - control: toggle vertical installation ComPact: fixed NS630b...1000 - control: toggle vertical installation ComPact: fixed NS1250 - control: toggle vertical installation ComPact: fixed NS630b...1000 - control: direct front rotary handle vertical installation ComPact: fixed NS1250 - control: direct front rotary handle vertical installation ComPact: fixed NS630b...1000 - control: motor mechanism vertical installation ComPact: fixed NS1250 - control: motor mechanism vertical installation ComPact: fixed NS1600 - control: toggle vertical installation ComPact: fixed NS1600 - control: direct front rotary handle vertical installation ComPact: fixed NS1600 - control: motor mechanism vertical installation ComPact: drawout NS1600 - control: direct front rotary handle vertical installation ComPact: drawout NS1600 - control: motor mechanism vertical installation ComPact: drawout NS1600 - control: toggle vertical installation Masterpact: fixed NT06...10 - control: toggle vertical installation Masterpact: fixed NT06...10 - control: motor mechanism vertical installation Masterpact: fixed NT12 - control: toggle vertical installation Masterpact: fixed NT12 - control: motor mechanism vertical installation Masterpact: fixed NT16 - control: toggle vertical installation Masterpact: fixed NT16 - control: motor mechanism vertical installation
[Ie] rated operational current	1600 A
Colour	Natural
Height	410 mm
Width	600 mm

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Depth	285 mm
Net weight	32.42 kg
Quantity per set	Set of 1

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	43.0 cm
Package 1 Width	25.0 cm
Package 1 Length	62.0 cm
Package 1 Weight	32.75 kg
Unit Type of Package 2	P06
Number of Units in Package 2	2
Package 2 Height	59.0 cm
Package 2 Width	60.0 cm
Package 2 Length	80.0 cm
Package 2 Weight	71.5 kg

Logistical informations

Country of origin	HU
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint	
Environmental Disclosure	Product Environmental Profile

Use Better


Materials and Substances	
Packaging made with recycled cardboard	Yes
Packaging without single use plastic	No
EU RoHS Directive	Compliant
REACH Regulation	REACH Declaration

Use Again

Repack and remanufacture	
Circularity Profile	No need of specific recycling operations
Take-back	No

Technical Illustration

Dimensions

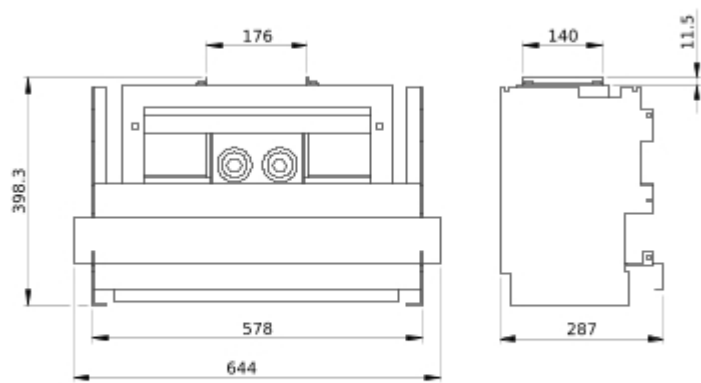

- All dimensions are approximate and are in mm
- Also see technical documentation.