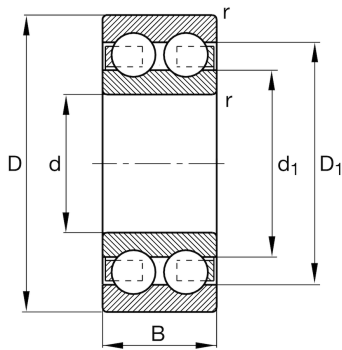
**FAG****4208-BB-TVH**

Deep groove ball bearing

Schaeffler ID:
0219434940000Deep groove ball bearing 42...BB-TVH,
double row, plastic cage

Technical information

**Main Dimensions & Performance Data**

d	40 mm	Bore diameter
D	80 mm	Outside diameter
B	23 mm	Width
C_r	42.000 N	Basic dynamic load rating, radial
C_{0r}	34.500 N	Basic static load rating, radial
C_{ur}	1.790 N	Fatigue load limit, radial
n_G	7.200 1/min	Limiting speed
n_{gr}	7.500 1/min	Reference speed
	0,496 kg	Weight

Mounting dimensions

$d_{a \min}$	47 mm	Minimum diameter shaft shoulder
$D_{a \max}$	73 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1 mm	Maximum fillet radius

Dimensions

r_{\min}	1,1 mm	Minimum chamfer dimension
D_1	67,2 mm	Shoulder diameter outer ring
d_1	53 mm	Shoulder diameter inner ring

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.

Calculation factors

f_0	14,7	Calculation factor
-------	------	--------------------

