




English	Français	Deutsch	Italiano	Español
Dome head	Tête plate	Flachrundkopf	Testa Tonda	Cabeza alomada
Body: Stainless steel* Natural	Corps: Inox* Brut	Hülse: Edelstahl* Unbehandelt	Corpo: Acciaio inox* Nessuna finitura	Cuerpo: Acero inoxidable* Natural
Stem: Stainless steel Natural	Tige: Inox Brut	Dorn: Edelstahl Unbehandelt	Gambo: Acciaio inox Nessuna finitura	Vástago: Acero inoxidable Natural

*: 300 Series

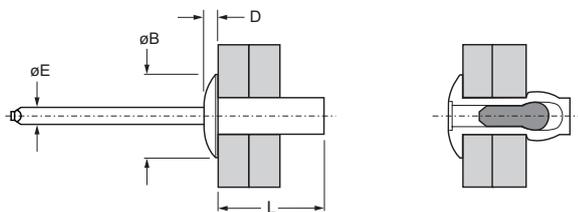

ø nom.					L ref.	øE ref.	øB max.	D max.	 kN ¹⁾	 kN ¹⁾	Part No.
	min.	max.	min.	max.							
3.2 (1/8")		1.6	3.3	3.4	6.6	2.0	6.7	0.9	2.10	2.22	TD 42 GT
	1.6	3.2			8.0						TD 44 GT
	3.2	4.8			9.7						TD 46 GT
	4.8	6.4			11.3						TD 48 GT
	6.4	7.9			12.9						TD 410 GT
4.0 (5/32")		3.2	4.1	4.2	8.6	2.36	8.3	1.0	3.30	4.00	TD 54 GT
	3.2	4.8			10.2						TD 56 GT
	4.8	6.4			11.8						TD 58 GT
	6.4	7.9			13.4						TD 510 GT
4.8 (3/16")		3.2	4.9	5.0	9.2	2.97	10.0	1.25	4.30	4.40	TD 64 GT
	3.2	4.8			10.8						TD 66 GT
	4.8	6.4			12.5						TD 68 GT
	6.4	9.5			15.5						TD 612 GT
	9.5	12.7			18.5						TD 616 GT
6.4 (1/4")		6.4	6.5	6.6	14.2	3.93	13.0	1.35	6.80	8.70	TD 808 GT
	6.4	7.9			15.7						TD 810 GT
	7.9	12.7			20.5						TD 816 GT

all dimensions in mm / en millimètre / alle Maße in mm / in millimetri / en milímetros

1) typical values / valeurs moyennes / typische Werte / Valori tipici / valores típicos