



SIVACON, side panel / rear panel, Closed, IP55, H: 2200 mm, W: 400 mm, RAL 7035

Model		
product brand name	SIVACON	
product designation	Side panel/rear panel	
design of the product	Closed	
design of the surface	Powder-coated	
design of the product EMC version	No	
Protection class		
protection class IP	IP55	
Appearance		
RAL color number	RAL 7035	
color	light grey	
Product details		
product component		
• cable entry		
• lock		
Mechanical Design		
height	2 200 mm	
width	400 mm	
depth	400 mm	
material	steel	
Approvals Certificates		
General Product Approval		Test Certificates
		other



[Special Test Certificate](#)

[Miscellaneous](#)

[Confirmation](#)

other

Environment

[Miscellaneous](#)

Siemens
EcoTech



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1240-2UW61-1C>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1240-2UW61-1C>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1240-2UW61-1C

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

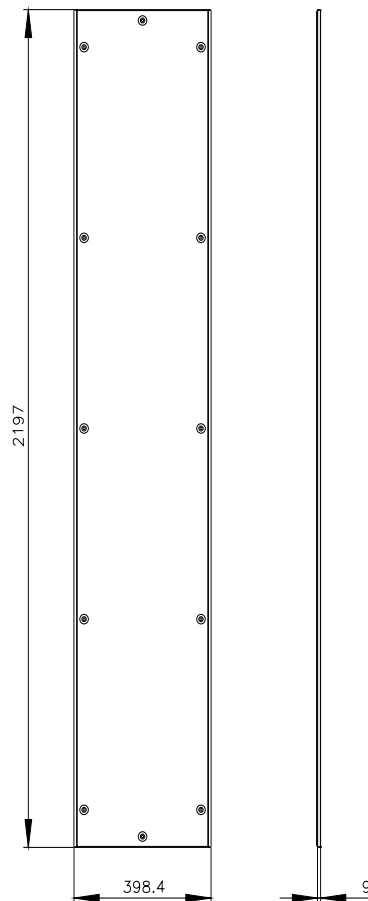

last modified:

2/5/2021 

