




SIVACON, side panel / rear panel, Closed, IP40, H: 1800 mm, W: 900 mm, RAL 7035

Model			
product brand name		SIVACON	
product designation		Side panel/rear panel	
design of the product		Closed	
design of the surface		Powder-coated	
design of the product EMC version		No	
Protection class			
protection class IP		IP40	
Appearance			
RAL color number		RAL 7035	
color		light grey	
Product details			
product component			
• cable entry		No	
• lock		No	
Mechanical Design			
height		1 800 mm	
width		900 mm	
depth		900 mm	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other
		Special Test Certificate	Confirmation
			Miscellaneous
			

Further information	
Information on the packaging	
https://support.industry.siemens.com/cs/ww/en/view/109813875	
Information- and Downloadcenter (Catalogs, Brochures,...)	
http://www.siemens.com/lowvoltage/catalogs	

Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1890-2UW60-1C>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1890-2UW60-1C>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1890-2UW60-1C
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

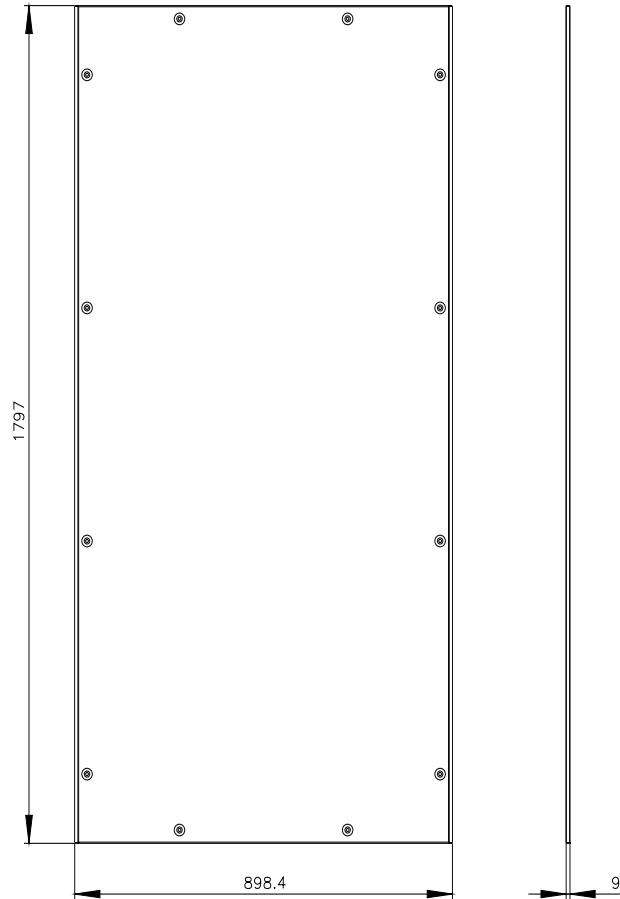

last modified: 5/24/2025

