

模块化信号塔灯 / KombiSIGN 72

**AndonLIGHT KS72 GN/YE/RD**



零件号:	<b>649.000.03</b>
系列:	<b>KombiSIGN 72</b>

**机械参数**

Length	92 mm
Width	32 mm
Height	160 mm
Diameter	70 mm
Materials	PA-GF PC
Dome colour	Green Red Yellow
Housing colour	Black
Protection category	IP30
Connection	Spring-type terminal
cross-sectional area maximum	1,50mm <sup>2</sup> / 16AWG
Cable entry	Through hole
Cable entry maximum	d = 11 mm
Tension relief	Not present
Type of fixing	Tube mounting
Working temperature minimum	0°C
Working temperature maximum	+40°C
包装重量	1117 g
净重□g□	1003 g

**电气参数**

Operating voltage	115-230V
Operating voltage type	AC
Operating voltage frequency	50Hz at 230V 60Hz at 115V
Operating voltage tolerance	+/- 10%
Rated operational voltage	230 VAC
Rated operational current	65 mA
Rated inrush current	>10A
Protection class	Protection class 2
Pollution degree	3
Overvoltage category	II
Isolation voltage	Ui = 250V; Uimp = 2.500V

**光学参数**

Light source	LED
--------------	-----

! 有关其他安装和安装信息，请参阅www.werma.com.cn上的相应用户指南。 本印刷版仅供参考，如有更改，恕不另行通知。

模块化信号塔灯 / KombiSIGN 72



**AndonLIGHT KS72 GN/YE/RD**

Light colour	Green Red Yellow
Optical signal image	Permanent
Blink frequency (Hz)	1 Hz
Service life optical	50,000 h maximum



有关其他安装和安装信息，请参阅[www.werma.com.cn](http://www.werma.com.cn)上的相应用户指南。 本印刷版仅供参考，如有更改，恕不另行通知。

模块化信号塔灯 / KombiSIGN 72  
**AndonLIGHT KS72 GN/YE/RD**

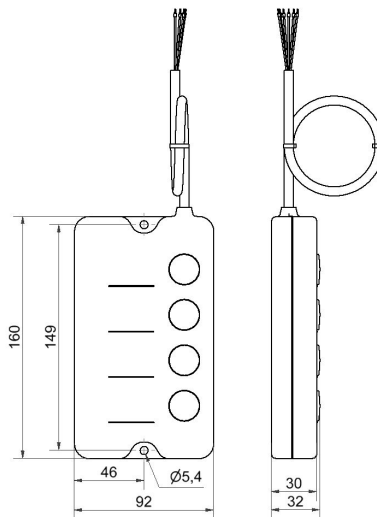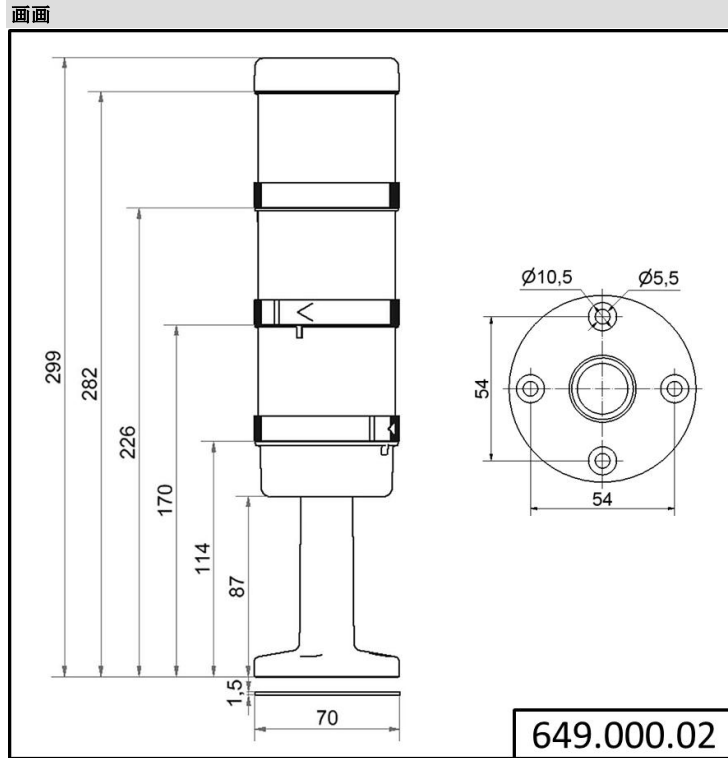

! 有关其他安装和安装信息，请参阅[www.werma.com.cn](http://www.werma.com.cn)上的相应用户指南。 本印刷版仅供参考，如有更改，恕不另行通知。