


# Switchcraft®

[Previous Page](#) | [Return to Index](#) | [Next Page](#)

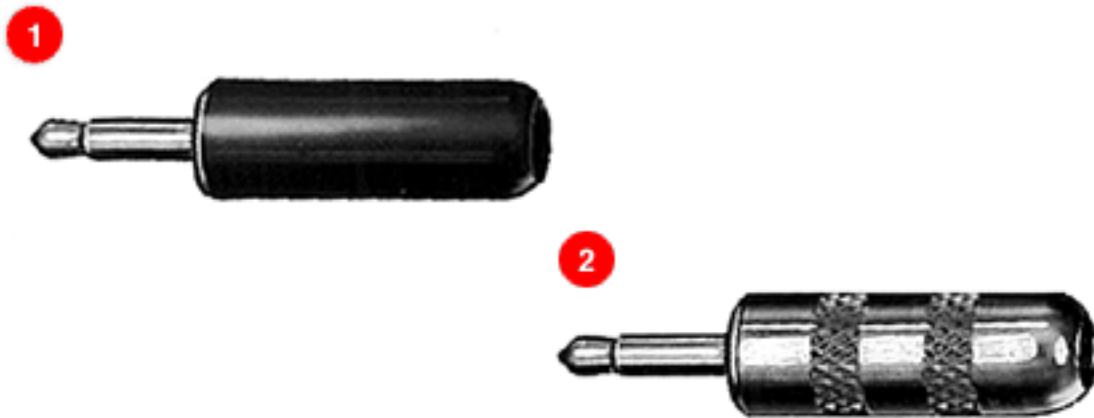

## .141 MINIATURE PHONE PLUGS

**1. Number 750**

**2. Number 780**

[click here to download a schematic drawing](#)

(you will need to have Adobe Acrobat installed on your system to do this)



## FEATURES

\* Miniature 2-conductor Phone Plug for use with Switchcraft Tini-Jax® miniature phone jacks. About 1/2 the size of Switchcraft Littel-Plug® phone plug. Average net weight, 1/8 ounce.

\* Various terminal combinations:

(a) Dual purpose sleeve terminal may be clamped over metal braid or shielded cables; provides cable anchor. Easily soldered for perfect electrical connection.

(b) Screw terminal design (no cable clamp) for cable. Terminals that can be more suitably connected by screws.

\* 1-piece tip rod staked into mating terminals; no disassembly of tip during use of plug. Terminals and body of plug interlocked mechanically.

\* Available in black or red plastic handles or brass nickel-plated handles for shielding. Can be used with cables up to .188 inch outside diameter.

## SPECIFICATIONS

**Sleeve, Tip and Body:** Nickel-plated copper alloy.

**Terminals:** Copper alloy, electro-tinned. Solder lug or screw type (Screws #0-80).

**Handle:** Molded black or red plastic. Copper alloy, nickel-plated.

Part No.	Terminals	Typical Mating Jack <sup>1</sup>	Handle	Part No.
740	Screw <sup>2</sup>	41	Black	M1055
745			Red	M1056
750	Black		M1055	
755	Solder Lug & Cable Clamp		Red	M1056
2P1384			Less Handle	----
770	Screw <sup>2</sup>		Shielded	T13631
780	Solder Lug & Cable Clamp		Shielded	T13631