

## DIN-Power F-shroud for SH D20 3,2

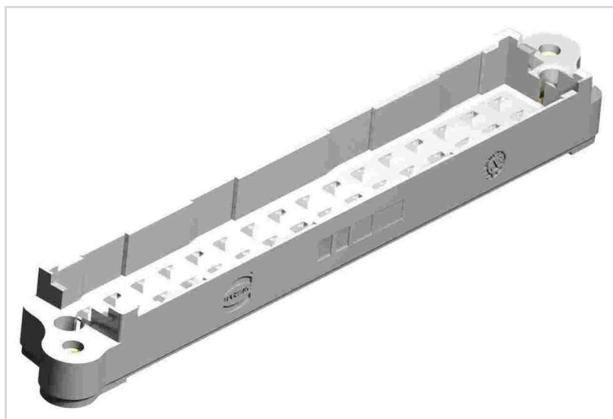


Image is for illustration purposes only. Please refer to product description.

Part number	09 06 002 9921
Specification	DIN-Power F-shroud for SH D20 3,2
HARTING eCatalogue	<a href="https://harting.com/09060029921">https://harting.com/09060029921</a>

### Identification

Category	Accessories
Series	DIN 41612
Type of accessory	Pin shroud
Description of the accessory	for type F "low profile" with press-in pins Without locking levers

### Version

Termination length	13 mm
Fixing	Screw fixing

### Technical characteristics

Isolation group	IIIa ( $175 \leq CTI < 400$ )
PCB thickness	3.2 mm +0.8

### Material properties

Material (accessories)	Thermoplastic
Colour (accessories)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel

## Specifications and approvals

Railway classification	F1/I2 acc. to NFF 16-101/102
------------------------	------------------------------

## Commercial data

Packaging size	20
Net weight	7.32 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140010796
eCl@ss	27440292 Connector component (accessories)
ETIM	EC002943
UNSPSC 24.0	39121400