

NT 22/1 AP BP L

Compact and versatile battery powered wet and dry vacuum cleaner NT 22/1 Ap Bp for demanding wet and dry applications at locations without an external power supply. With space-saving flat pleated filter.



Made in Europe



BATTERY NOT INCLUDED



REAL TIME TECHNOLOGY



Order no.

1.528-130.0

- 22-litre container, compact design, low weight, dust class L
- Semi-automatic filter cleaning Ap, battery-powered machine from the 36 V platform
- 300 mm floor nozzle, crevice nozzle, Dry flat pleated filter

Technical data

EAN code		4054278672328
Battery platform		36 V battery platform
Container capacity	l	22
Container material		Plastic
Sound pressure level	dB(A)	70
Air flow	l/s	57
Vacuum	mbar / kPa	152 / 15.2
Rated input power	W	max. 575
Standard nominal width		ID 35
Number of batteries required	Piece(s)	1
Performance per battery charge	m²	approx. 150 (7.5 Ah)
Run time per battery charge	min	max. 31 (7.5 Ah) / max. 24 (6.0 Ah)
Battery charging time with quick charger 80% / 100%	min	58 / 81
Charging current	A	6
Power supply for battery charger	V / Hz	100 - 240 / 50 - 60
Colour		anthracite
Weight without accessories	kg	8.8
Weight incl. packaging	kg	11.1
Dimensions (L × W × H)	mm	401 × 372 × 499

Equipment

Versions		Battery and battery charger not included
Suction hose length	m	1.9
Suction hose type		with bend
Quantity of suction tubes	Piece(s)	2
Suction tubes length	mm	505
Suction tubes material		Plastic
Filter bag material		Fleece
Wet/dry floor nozzle width	mm	300
Crevice nozzle		■
Automatic cut-out features at max. filling quality		■
Flat pleated filter		Cellulose fibre material
Filter cleaning		Semi-automatic filter cleaning
Protection class		III

■ included in the scope of supply.




Powerful 36 V Kärcher Battery Power+ battery with 7.5 Ah capacity

- Ensures a long runtime of 31 minutes at full suction power.



Effective protection cover for the battery bay

- Protects the battery from dirt and moisture. With viewing window.

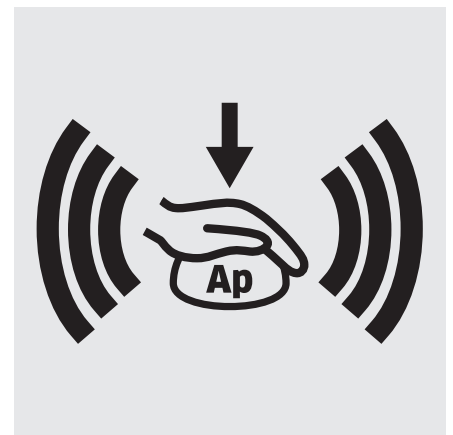

Semi-automatic filter cleaning

- Semi-automatic filter cleaning guarantees constantly high suction power.
- The positioning of the Ap cleaning button simplifies handling.


ACCESSORIES FOR NT 22/1 AP BP L 1.528-130.0



	Order no.	Description	
FLAT PLEATED FILTER, STANDARD, BIA C OR UP TO DUST CLASS M			
Flat pleated filter, paper			
Flat pleated filter, paper	1	6.904-156.0	For wet and dry vacuum cleaners NT 14/1 and NT 22/1 Ap Bp: flat pleated filter Dry made from cellulose fibre material for vacuuming fine dust and coarse dirt from dust classes L and M. With green label. ■
Flat pleated filter, PES			
Flat pleated filter, PES	2	6.906-123.0	Flat pleated filter (PES) – BIA-C dust class M: rotproof polyester fleece, ideal for wet use and abrasives. Optional main filter for NT 14/1 and NT 351 Eco/Professional. □
Flat pleated filter, PTFE			
Wet & Dry flat pleated filter, PES fibre material with PTFE coating, suitable for NT 22/1 Ap Bp	3	6.907-649.0	Wet & Dry flat pleated filter made from PES fibre material with PTFE coating with a blue label. Suitable for vacuuming liquids, fine dust and coarse dirt from the M and L dust classes. □
BENDS			
Bend, plastic			
Bend, NT, DN 35, plastic, clip 2.0 at hose end, cone at accessory end	4	2.889-199.0	DN 35 plastic bend for wet and dry vacuum cleaners. Equipped with a clip 2.0 connection at the hose end and a cone connection at the accessory end. ■
SUCTION NOZZLES			
Floor nozzles			
Wet/dry floor nozzle, DN 35, width 300 mm, with parking hook	5	2.899-811.0	Plastic wet/dry floor nozzle with parking hook, brush strips and squeegees in DN 35. For wet and dry vacuuming of fine dust, coarse dirt or liquids. Width of 300 mm. ■
Crevice nozzles			
Crevice nozzle, DN 35, plastic, 225 mm	6	2.889-159.0	Crevice nozzle with nominal width DN 35 for Kärcher dry vacuum cleaners and wet and dry vacuum cleaners. Length 225 mm. ■
Car cleaning nozzles			
Ergonomic car nozzle, ID 35, 100 mm	7	2.889-356.0	Ergonomic and compact DN 35 car cleaning nozzle made from plastic with a working width of 100 mm for vehicle interior cleaning. Suitable for all wet and dry vacuum cleaners with DN 35 bends. □
Car nozzle, ID 35, 90 mm	8	6.906-108.0	Flat angled, convenient, plastic, DN 35 car cleaning nozzle designed for all Kärcher wet and dry vacuum cleaners with bends. Working width: Approx. 90 mm. □
SUCTION TUBES			
Suction tubes, plastic			
Suction tube, 2 x, HV and NT, DN 35, 505 mm long, plastic, suitable for: HV 1/1 Bp, NT 22/1, NT 27/1, NT 48/1, ProNT 600 L	9	2.889-218.0	The suction tube set consists of 2 suction tubes made of high-quality plastic (DN 35 and 505 mm long each). For the HV 1/1 Bp battery-powered hand vacuum cleaner as well as wet and dry vacuum cleaners from Kärcher. ■
Suction tubes, metal			
Suction tube, DN 35, 505 mm long, chrome-plated steel, suitable for: T 7/1, T 10/1, T 12/1, NT 22/1, NT 30/1, NT 40/1, NT 50/1, NT 65/2	10	6.902-074.0	Chrome-plated steel suction tube for Kärcher dry vacuum cleaners and wet and dry vacuum cleaners, nominal width DN 35 and 505 mm long. □
BATTERIES			
Battery Power 36/50	11	2.445-031.0	36 V / 5.0 Ah Battery Power exchangeable battery with innovative Real Time Technology incl. LCD display to show the battery level. Suitable for all devices on the 36 V Kärcher battery platform. □
BATTERY CHARGERS			
Fast Charger Battery Power 36 V	12	2.445-033.0	With the fast charger, the 36 V/2.5 Ah exchangeable battery can be charged to 80% in just 48 minutes. Also suitable for all other batteries on the 36 V Kärcher battery platform. □
STARTERKIT BATTERIES AND BATTERY CHARGERS			
Starter kit Battery Power 36/50	13	2.445-065.0	Battery Power 36/50 Starter Kit incl. 36 V/5.0 Ah Battery Power exchangeable battery and 36 V fast charger. Suitable for use in all devices on the 36 V Kärcher battery platform. □
BATTERIES			
Battery Power+ 36/75	14	2.445-043.0	A capacity of 7.5 Ah guarantees long runtimes for the Battery Power+ 36 V lithium-ion battery. Very powerful, with Real Time Technology via LCD display and protection against overcurrent. □

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR NT 22/1 AP BP L 1.528-130.0

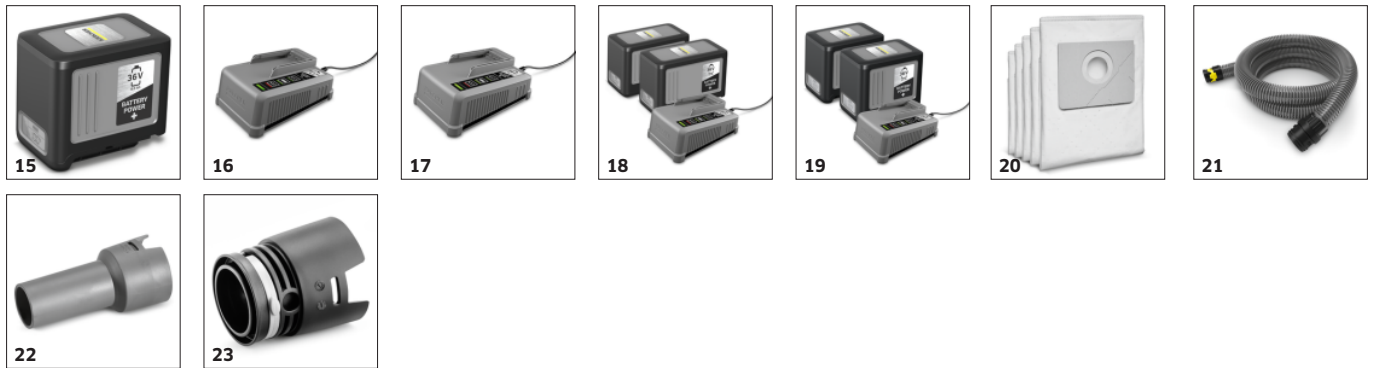

		Order no.	Description	
BATTERIES				
Battery Power+ 36/60	15	2.042-022.0	Extremely powerful Battery Power+ 36 V lithium-ion battery with a capacity of 6.0 Ah for a long runtime. With innovative Real Time Technology via LCD display and voltage monitoring.	<input type="checkbox"/>
BATTERY CHARGERS				
Universal charger Battery Power+ 18-36	16	2.445-054.0	Universal charging unit Battery Power+ with LED operating status indicator for charging all 18 and 36 V Kärcher Battery Power and Kärcher Battery Power+ lithium-ion batteries. Suitable for wall mounting.	<input type="checkbox"/>
Fast charger Battery Power+ 36/60	17	2.445-045.0	Charge all 36 V Kärcher Battery Power and Kärcher Battery Power+ lithium-ion batteries with max. 6 A charging current: Quick charger with LED operating status indicator. Easy wall mounting.	<input type="checkbox"/>
STARTER KIT				
Starter kit Battery Power+ 36/75	18	2.445-070.0	Starter Kit Battery Power+ 36/75 with 2 36-V/7.5-Ah batteries and 36-V quick charger for our 36 V Kärcher Battery Power and Kärcher Battery Power+ battery platform devices.	<input type="checkbox"/>
Starter kit Battery Power+ 36/60	19	2.445-071.0	Kärcher Battery Power+ 36/60 Starter Kit for all machines in the Kärcher 36 V Battery Power+ battery platform. Scope of delivery: 2x 36 V/6.0 Ah batteries and the compatible 36 V quick charger.	<input type="checkbox"/>
FILTER BAGS				
Fleece filter bags				
Fleece filter bags, 5 Piece(s), NT 22/1	20	6.907-469.0	Tear-resistant 3-layer fleece filter bags of dust class M, suitable for Kärcher wet and dry vacuum cleaners. Contents: 5-pack.	<input type="checkbox"/>
SUCTION HOSES				
Suction hoses with clip system 2.0 (compatible with vacuum cleaners from model year 2017 on)				
Suction hose, NT, DN 35, length 2.5 m, clip 2.0, bayonet 2.0	21	2.889-134.0	The suction hose in nominal width DN 35 and with 2.5 m length is suitable for use with wet and dry vacuum cleaners from Kärcher.	<input type="checkbox"/>
CONNECTING SLEEVES				
Connection adapter C ID (clip to cone)				
Adapter clip DN 35 on cone DN 35	22	5.407-005.0	Adapter clip system DN 35 for connecting suction tubes and small nozzles to cone DN 35. Perfect for vehicle interior cleaning, even without the connection of other nozzles.	<input type="checkbox"/>
OTHER ACCESSORIES NT				
Adapter clip new on clip old DN 35	23	2.889-312.0	Adapter for connection of hoses of the new accessory system of dry and wet and dry vacuum cleaners to bends or extension hoses of the old system. For nominal width DN 35.	<input type="checkbox"/>

■ Included in the scope of supply. □ Available accessories.