


5

4

3

2

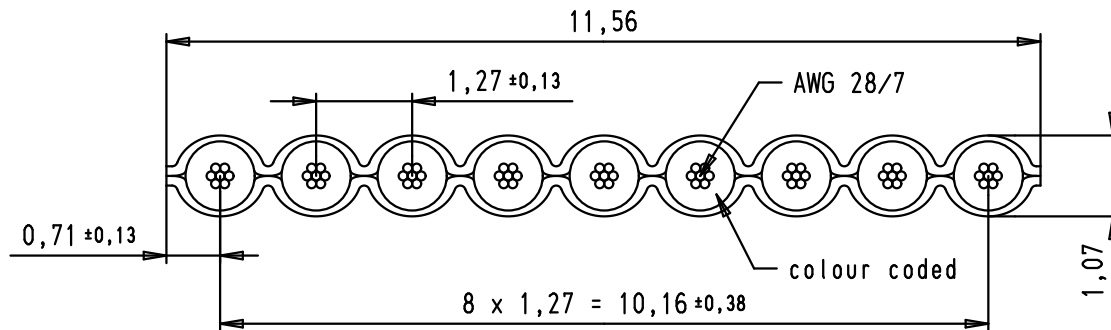

1



Wire	Cu tinned
Gauge	AWG 28/7
Voltage rating	300 Vr.m.s
Conductor resistance	221 mΩ/m
Capacity unbalanced	42,7 pF/m
Impedance unbalanced	105 Ω
Inductance unbalanced	0,68 μH/m
Signal delay	4,9 ns/m
Insulation material	PVC
Temperature rating	-20°C to +105°C
Flammability rating	UL: VW1
Insulation resistance	10 000 MΩ/km

Colour code sequence (in 10 steps):

- brown
- red
- orange
- yellow
- green
- blue
- violet
- grey
- white
- black

				Dot.	Name	 All Dim. in mm Orig. Size DIN A 4	SEK 18 Flat cable	Maßstab/ Scale
			Detail.	14/05/07	PK		9 poles, length per reel: 30,48 m colour coded, UL 20130, IEC 918	10:1
			Insp.					
			Stand.					
							TB 09 18 009 7005	Blatt/ Page
33990	14/05/07	PK	HARTING EURL F-95972 Paris					Sub.
Mod.	Dot.	Name						