




PRODUCT DATASHEET

Datasheet creation date: 2025/07/08 2:18 (UTC)



6009ZZ

Single-Row Deep Groove Ball Bearings

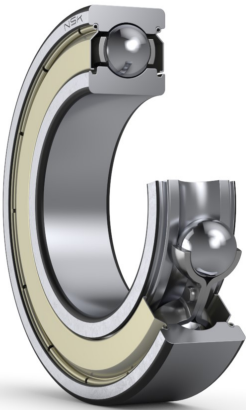

Boundary Dimensions

d	45	mm	Bore diameter
D	75	mm	Outside diameter
B	16	mm	Width
r (min.)	1	mm	Chamfer dimension

Basic Load Ratings

Cr	23000	N	Basic dynamic load rating
C0r	15200	N	Basic static load rating

Speeds

Grease	10000	min-1	Grease lubrication
--------	-------	-------	--------------------

Abutment and Fillet Dimensions

da (min.)	50	mm	Diameter of shaft abutment
da (max.)	53.5	mm	Diameter of shaft abutment
Da (max.)	70	mm	Diameter of housing abutment
ra (max.)	1	mm	Radius of shaft or housing fillet

Calculation factors

fo	15.3		Factor
----	------	--	--------

Additional information

z	13		Number of Balls
Dw	8.731	mm	Ball Diameter

Mass

Mass approx.	0.241	kg	Mass approx.
--------------	-------	----	--------------

