


Datasheet

RS Pro Desktop Power Supply LH60A Series

RS Stock No: 188-769

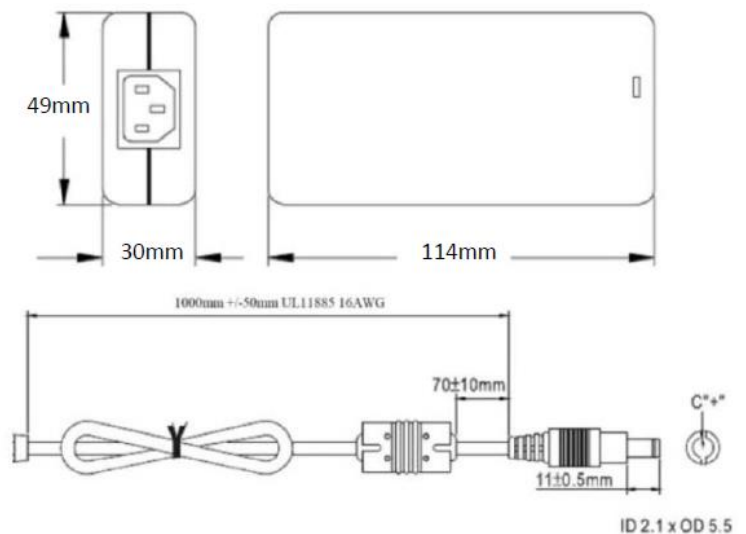

Features:

- 60W external power supply
- Protections: Over voltage, Overload, Short circuit and Over temperature
- Input voltage range: 100 to 240VAC
- No load power consumption: <math><0.5\text{W}</math>
- Fully enclosed plastic case
- LED indicator
- Efficiency: Up to 87%

**ENGLISH****Specifications:**

Model		188-769	732-0272	732-0275	188-781
Output	DC Voltage	12V	15V	18V	24V
	Rated Current	5.0A	4.0A	3.3A	2.5A
	Current Range	0-5.0A	0-4.0A	0-3.3A	0-2.5A
	Rated Power	60W			
Input	Voltage Range	100-240V ac			
	Frequency Range	47-63Hz			
	Efficiency	87%			
Protections	Short Circuit	Auto Recovery			
	Overload	Auto Recovery			
Environment	Working Temperature	0°C - 40°C			
Safety & EMC	Safety Standards	UL60950, UL6500, TUV: EN60950, EN60065 approved			
	EMC Emission	Compliance to EN55013, EN55020, EN55022, EN55024, EN61000-3-2, 3			
Other	Dimensions	114*49*30mm (L*W*H)			
Connector Plug		2.1mm	2.1mm	2.1mm	2.1mm