

# WI-FI SMA ANTENNA




## Mechanical/Environmental

Frequency range	2400 ~ 2483 MHz
Polarization	Linear (vertical)
Gain	5.0 dBi
V.S.W.R	2.0
Impedance	50 $\Omega$
Connector type	RP-SMA Male
Operating temperature	-40 °C ~ +85 °C
IP rating	IP33
RoHS compliant	✓


Radiation patterns

Wi-Fi - Antenna

ELEVATION

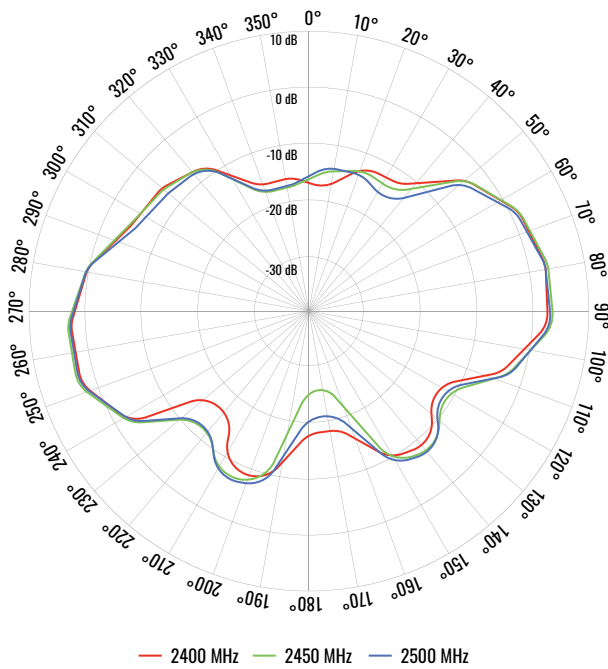

AZIMUTH

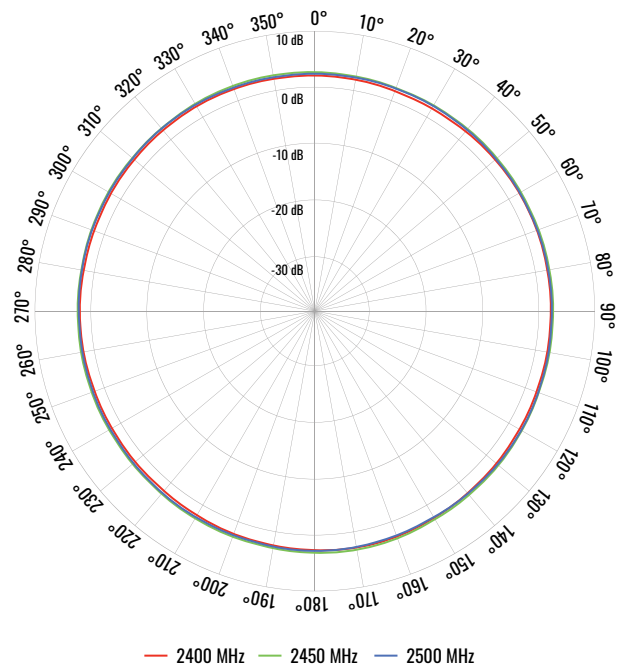

Spatial measurements

