



Features at a glance

- Halogen lamp
- Color temperature warm white 3,000 K
- Glare-free thanks to metal louver
- Black luminaire head of aluminum and plastic, glass screen
- Arm relieved by friction
- With switch in the luminaire head
- System of protection IP20; class of protection III
- Supplied without mains lead
- Various fastenings and transformers to connect to the mains voltage as an accessory

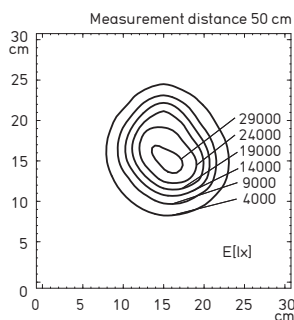


Illuminance based on the example 1 x 60 W

 Integrated machine luminaires



Surface-mounted luminaires

 

Tube luminaires



Arm-mounted luminaires



FITTED WITH	OPERATING DEVICE	CONNECTED LOAD	SPECIAL FEATURE	E_m / E_{max}^*	MODEL	ORDER NO.
1 x 60 W	–	24 VAC/DC	–	3243/29780 lx ¹	HGL 70	100 570 000
1 x 55 W	–	12 VAC/DC	–	2933/25050 lx ¹	HGL 70	100 570 010

* E_m = medium illuminance; E_{max} = maximum illuminance

¹ Measuring range 30 cm x 30 cm/Measuring distance 50 cm

Also available as an pivoting-head luminaire