



<b>Application</b>	Commercial, Education, Healthcare, Hospitality, Retail
<b>Specification</b>	Architectural

# Vasco EVO

Vasco EVO CCT Multi Wattage 1200mm Silver

**Code:** AVAS4/1/S




## Varied Mounting Options

Flexible installation with surface, suspension, track and wall mounting options available



## Interchangeable Reflector

Specially designed optics allows to achieve UGR19 low glare rating. Simply unclip the end cap and replace the diffuser.  
\*Opal diffuser supplied as standard (UGR23)

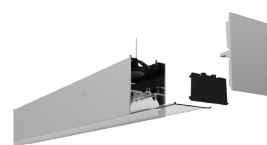

## PRODUCT FEATURES

- Aluminium bi-directional suspended or surface linear suitable for education, commercial and retail applications
- High efficiency upto 150lm/W (only when fitted with UGR diffuser - AVAS\*/1/UGR)
- CCT selectable between 3000K and 4000K and power selectable; offering a choice of 2 outputs, in one luminaire
- Pre-wired with 1.5 metre cable
- Bi-directional light output as standard with 30% upward light and 70% downward light ratio (downward only option can be selected if required, please note light output changes in downward only mode)
- Opal diffuser (provided as standard) provides optimal light uniformity
- PIR end cap accessory available
- Adjustable suspension points c/w suspension kit

## GENERAL INFORMATION

<b>Wattage</b>	14W - 32W
<b>Lumens Delivered</b>	1500lm - 3400lm (4000K) / 2000lm - 4600lm (4000K w/ AVAS4/1/UGR)
<b>Lm/W</b>	105lm/W (150lm/W w/ AVAS4/1/UGR)
<b>Beam Angle</b>	110
<b>CRI</b>	80
<b>CCT</b>	3000K/4000K
<b>Input</b>	220-240V
<b>Operating Temp</b>	-20°C to 45°C
<b>SDCM</b>	3
<b>UGR</b>	23
<b>Product Weight without Packaging</b>	2.74 kg

## TECHNICAL INFORMATION

<b>Light Source</b>	LED
<b>Colour / Finish</b>	Silver
<b>IP Rating</b>	IP40
<b>IK Rating</b>	IK06
<b>Class Protection</b>	1
<b>Internal / External</b>	Internal
<b>Surface / Recessed / Suspended</b>	Surface, Suspended
<b>Lumen Depreciation</b>	L80 100,000h
<b>Warranty (Years)</b>	5
<b>CE Mark</b>	Yes
<b>Height</b>	75 mm





<b>Application</b>	Commercial, Education, Healthcare, Hospitality, Retail
<b>Specification</b>	Architectural

# Vasco EVO

Vasco EVO CCT Multi Wattage 1200mm Silver

**Code:** AVAS4/1/S

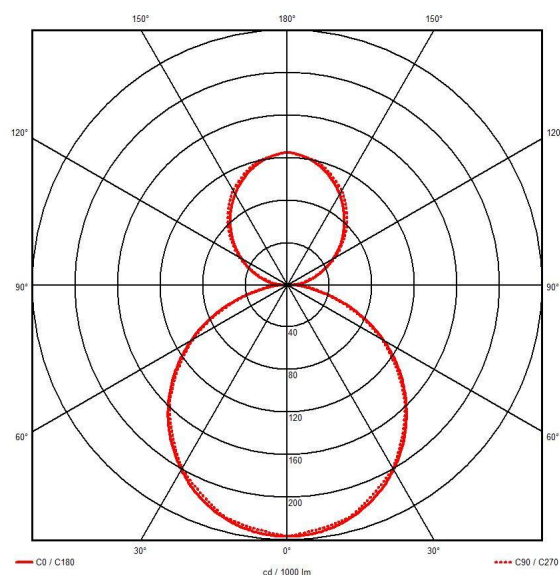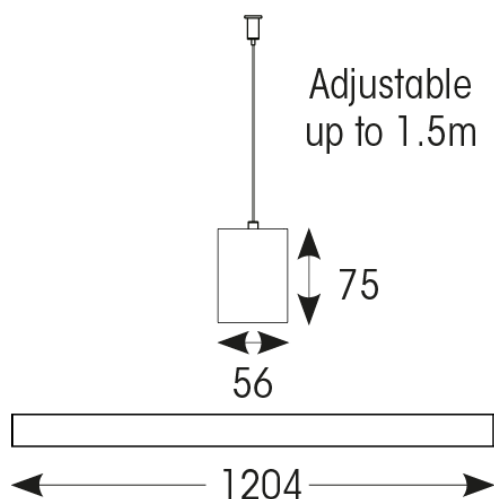

## ACCESSORIES

AVAS/1/1200/S	Vasco EVO Infill 1200mm Silver
AVAS4/1/UGR	Vasco EVO UGR19 Reflector 1200mm
AVASLED/SK	Vasco CCT Suspension Kit Aluminium
AVASLED/90	Vasco CCT 90° Corner Connector Aluminium
AVAS/WM/1	Vasco Wall Mounting Kit
AVAS/P3/2/W	Vasco Three Circuit Track Adaptor White