

# ARCA 504021ST No MP



Sample image

**Order symbol :** ARCA 504021ST No MP

**Product nr :** 8121091N

**Description :** Cabinet, PC



**Remarks :** Transparent cover, Swinghandle, hinges on the long side, without mountingplate

**EAN :** 6418074318923

**El. number :**

- Finland : 3425155
- Denmark : 8212056378
- Sweden : 2507061

**Including :** Cabinet base, door with PUR gasket. 3mm double bit lock(s) with key. S versions with swinghandle 2-point locking system. Door guide included.

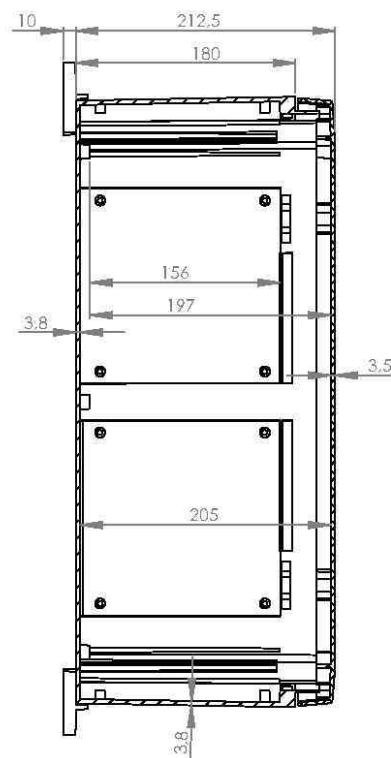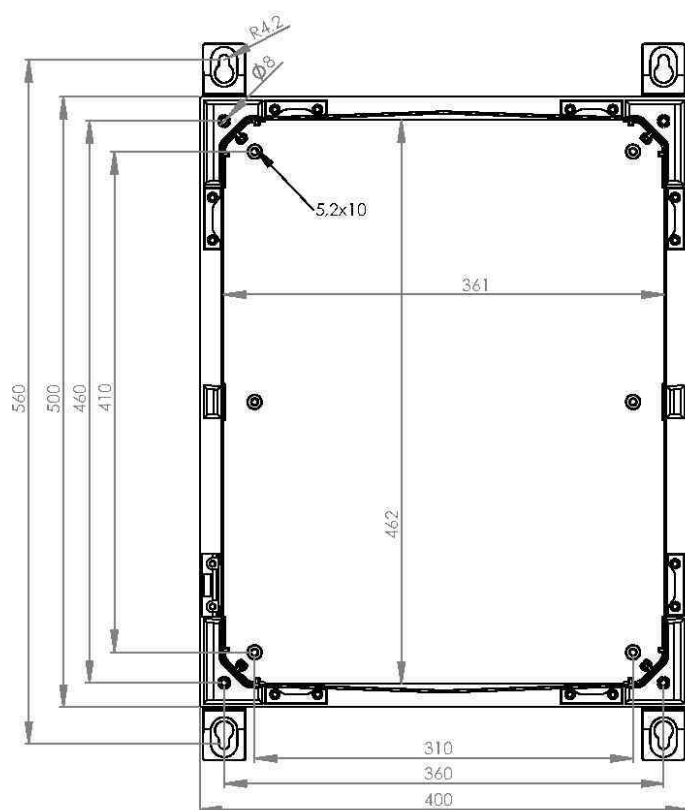

#### Dimensions :

|        |       |       |      |
|--------|-------|-------|------|
| mm :   | 500   | 400   | 210  |
| inch : | 19.69 | 15.75 | 8.27 |

#### Materials :

|                   |               |
|-------------------|---------------|
| Material :        | Polycarbonate |
| Base colour :     | RAL_7035      |
| Cover colour :    | Smoked grey   |
| Gasket material : | Polyurethane  |

#### Temperatures :

|                               |             |
|-------------------------------|-------------|
| Temperature °C (continuous) : | -40 ... 80  |
| Temperature °F (continuous) : | -40 ... 175 |

#### Accessories :

|                 |                                                                           |
|-----------------|---------------------------------------------------------------------------|
| IDS ARCA 5040   | Inner door set (485 x 385 x 35)                                           |
| MPX ARCA 5040   | Mounting plate (450x350 mm) (450 x 350 x 5)                               |
| MPMP ARCA 5040  | Mounting plate multiperforated (450x350x2 mm - ø3.6 mm) (450 x 350 x 1.5) |
| MPP ARCA 5040   | Mounting plate perforated (450x350x2 mm - 26x11 mm) (450 x 350 x 2)       |
| DRS ARCA 504021 | DIN rail frame set (485 x 385 x 35)                                       |
| PMK ARCA 40     | PoleMounting kit, for pole ø100-300mm (385 x 285 x 35)                    |
| DSP ARCA VLS    | Door stopper ARCA, vertical, left, small (15 x 104 x 16)                  |
| MPS ARCA 5040   | Mounting plate (450x350x2 mm) (450 x 350 x 2)                             |
| RCS ARCA 5040   | Rain canopy set for size 5040 and 4040 (30 x 400 x 20)                    |
| DSP ARCA VRS    | Door stopper ARCA, vertical, right, small (15 x 104 x 16)                 |

#### Ratings :

|                                         |                   |
|-----------------------------------------|-------------------|
| Ingress protection (EN 60529):          | IP65;             |
| Impact Resistance (EN 62262):           | IK09;             |
| electrical_insulation :                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes               |
| UV resistance :                         | UL 746C           |
| Flammability Rating :                   | UL 94 5VA         |
| Glow Wire Test (IEC 695-2-1) °C :       | 960C              |

**Certificates :**

Certificate FI 40467